
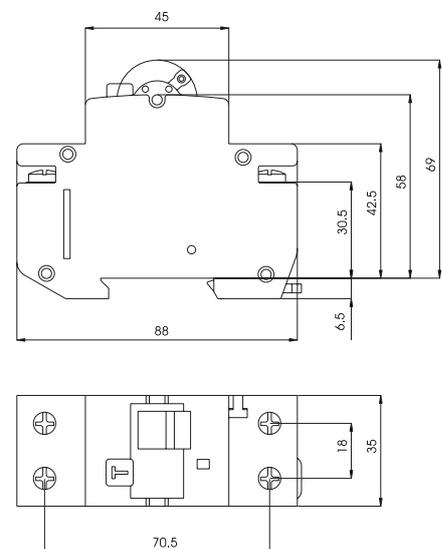


## RCBO 6kA 2 module 2-pole B or C - characteristic

Residual current circuit breaker with integral overcurrent protection. It is a 'Type A' RCBO and is capable of protecting the system against short-circuit current up to 6kA. It breaks both the phase and neutral conductors and can be supplied from the top or bottom.

Part numbers: RCBOGRB..., RCBOGRC...

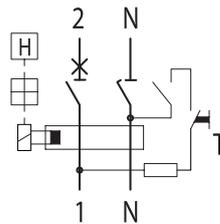

### Technical data

Rated voltage $U_n$	230V AC
Rated current $I_n$	6 - 40A
Rated frequency $f_n$	50 Hz
Rated short-circuit capacity	6 kA
Back-up fuse	100A gG
Tripping characteristic	B, C
Type	A
Rated residual current $I_{\Delta n}$	10, 30, 300 mA
Rated residual making & breaking capacity $I_{\Delta n}$	4,500A
Terminals	1-25mm <sup>2</sup> , max. 3Nm
Width	36 mm
Standards	IEC 61009, EN 61009