


Data Sheet

Push in fitting, Bulkhead Union

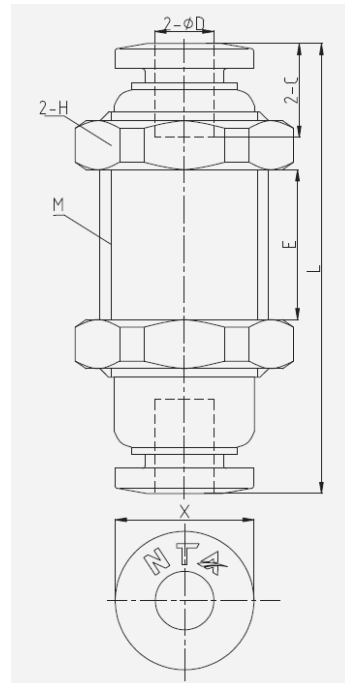

- Pressure range: 0 -10 bar
- Negative pressure: -1 bar (10 Torr)
- Max. pressure: 15 bar
- Temperature range: -10 – 80 °C

Item no.	Model no.	D	M	E	H	L	X	C
2615657	PM4	4	M12	10.4	14	31.6	9.9	14.8
2615658	PM6	6	M14	8.2	17	32.5	11.8	15.8
2615659	PM8	8	M16	8	19	35.5	13.8	17.3