


Data Sheet

G thread fitting, Male Elbow

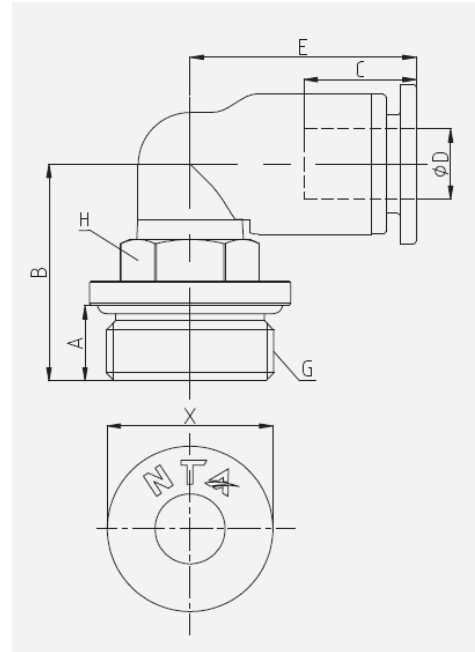

- Pressure range: 0 -10 bar
- Negative pressure: -1 bar (10 Torr)
- Max. pressure: 15 bar
- Temperature range: -10 – 80 °C

Item no.	Model no.	D	G	A	E	B	H	X	C
2615687	GPC6-G01	6	G1/8	5.5	20.5	24.8	10	11.8	16.7
2615688	GPC6-G02	6	G1/4	7	20.5	22	12	11.8	16.7
2615689	GPC8-G01	8	G1/8	5.5	23.3	25.5	14	13.8	19.1
2615690	GPC8-G02	8	G1/4	7	23.3	23.2	14	13.8	19.1
2615691	GPC12-G02	12	G1/4	7	29.3	30.6	17	19.8	24.4
2615692	GPC12-G03	12	G3/8	7	29.3	30.6	17	19.8	24.4
2615693	GPC12-G04	12	G1/2	8.5	29.3	28.9	17	19.8	24.4