


## Data Sheet

### Pneumatic connectors assortment box – 145 pcs

- Pressure range: 0 -10 bar
- Negative pressure: -1 bar (10 Torr)
- Max. pressure: 15 bar
- Temperature range: -10 – 80 °C




#### 1. Straight pieces – 70 pcs

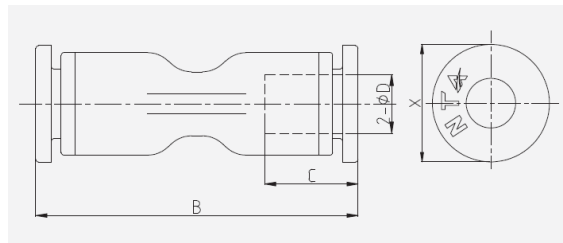

Item no.	Model no.	Qty	D	B	C	X
2615637	PU4	25	4	33.4	15.3	9.9
2615638	PU6	20	6	35.5	16.7	11.8
2615639	PU8	10	8	39.5	19.1	13.8
2615640	PU10	5	10	46.2	21.2	16.8
2615641	PU12	10	12	50.6	24.4	19.8


#### 2. Y-pieces – 15 pcs

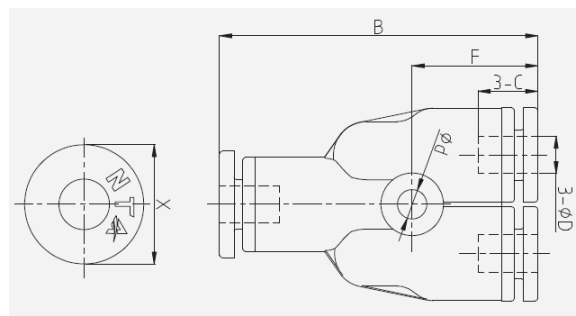

Item no.	Model no.	Qty	D	B	F	C	X	d
2615648	PY6	10	6	38.5	15	16.7	11.8	3.2
2615650	PY10	5	10	49	20.5	21.2	16.8	4.3


## Data Sheet

### 3. T-pieces – 20 pcs

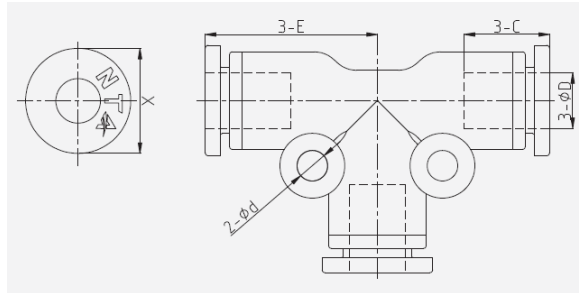


Item no.	Model no.	Qty	D	E	d	C	X
2615653	PE6	10	6	20.3	3.2	16.7	11.8
2615654	PE8	10	8	23.5	3.3	19.1	13.8

### 4. Straight pieces – 15 pcs

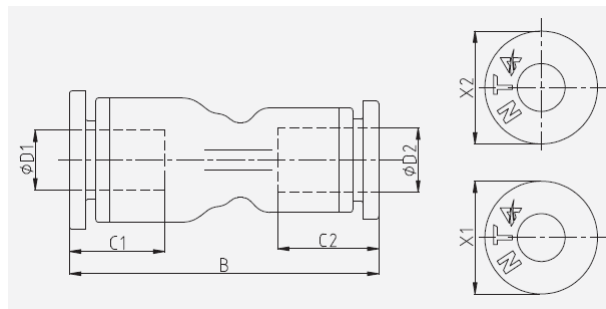

Item no.	Model no.	Qty	D1	D2	B	C1	C2	X1	X2
2615663	PG8-6	15	8	6	39	19.1	16.7	13.8	11.8

### 5. L-pieces – 25 pcs

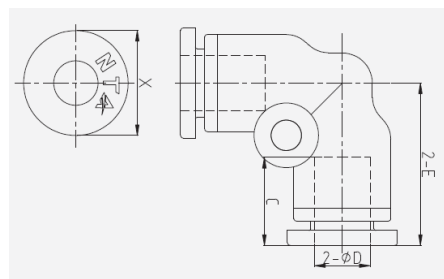

Item no.	Model no.	Qty	D	E	d	C	X
2615643	PV6	15	6	20.1	3.2	16.7	11.8
2615644	PV8	10	8	23.5	3.3	19.1	13.8