



Main

| | |
|------------------------------------|----------------------|
| Accessory / separate part category | Cabling accessory |
| Accessory / separate part type | Pre-wired connectors |
| Series name | General purpose |

Complementary

| | |
|--------------------------------|--------------------------------------|
| Electrical connection | M12, 4 pins elbowed female connector |
| Cable connector fixing | Screw-on |
| Collar material | Metal |
| Status LED | Without |
| Cable length | 10 m |
| Cable outer diameter | 4.6 mm |
| Cable composition | 4 x 0.25 mm ² |
| Wire insulation material | PVC |
| [Ue] rated operational voltage | 250 V AC 300 V DC |
| [In] rated current | 3 A |
| Contact resistance | 5000 µOhm |
| Insulating resistance | 1 GΩ |
| Product weight | 0.38 kg |

Environment

| | |
|---------------------------------------|----------------------|
| IP degree of protection | IP67 IP65 |
| Product certifications | CULus |
| Ambient air temperature for operation | -25...80 °C (static) |
| Ambient air temperature for storage | -25...80 °C |


Offer Sustainability

| | |
|--------------------------|--|
| Sustainable offer status | Not Green Premium product |
| RoHS (date code: YYWW) | Compliant - since 1201 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity |

Contractual warranty

| | |
|-----------------|-----------|
| Warranty period | 18 months |
|-----------------|-----------|


Dimensions

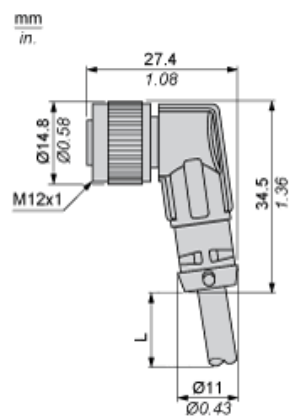

L : Length of cable

Connections and Schemes

Connector

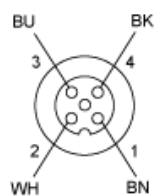

BN : Brown
BK : Black
BU : Blue
WH : White