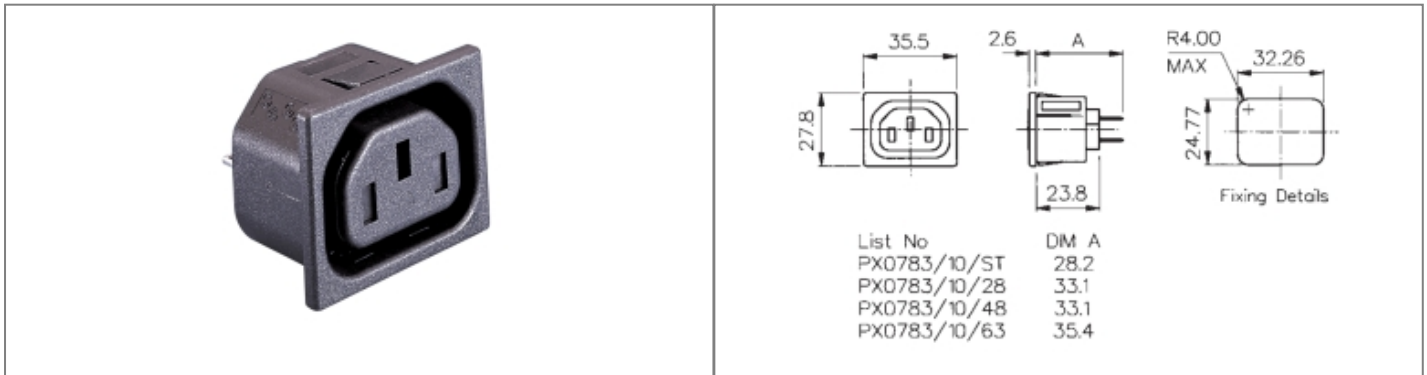


PX0783/15/63 Datasheet

Product Name // IEC Connector Snap Fit To Panel
Shuttered Outlet PX0783 Series 1.5mm Panel Black 6.3mm
Tab Termination EN60 320-2-2 Standard Sheet F Class I

[View Product Page](#)


// Product Description:

- ⊞ Snap Fit Panel Mount IEC Shuttered Outlets
- ⊞ EN60 320-2-2 Standard Sheet F Class I
- ⊞ Choice of panel thickness depending on part code: /10 - 1mm, /15 - 1.5mm, /20 - 2mm, /30 - 3mm
- ⊞ Choice of Termination depending on part code: /28 - 2.8mm Solder Tag, /48 - 4.8mm Tab, /63 - 6.3mm Tab, /ST - Solder Tag
- ⊞ Choice of colour depending on part code: /WH - White, /GY - Grey, no suffix - Black (some approvals apply to specific colour and/or Termination choices only - see data for details)
- ⊞ Insulation Boot for rear of connector available separately (part code 12075)
- ⊞ Blanking Cover for front of connector available separately (part code 14228)
- ⊞ Mate with PX0685, PX0686, PX0686/SE

// General Information:

Product Display Title:	Snap Fit Panel Mount IEC Shuttered Outlets
Product Family:	IEC Connectors
Product Series:	IEC60320 Main Inlets and Outlets
Approvals:	CSA, ENEC, UL, VDE
Body Material:	Nylon 66
Current Max:	10A, 15A
Flamability Rating:	UL94V-0
Function:	Panel Mount Connector
iec Connector Colour:	Black
iec Connector Mates With:	PX0685, PX0686, PX0686/SE
iec En60620 Type:	EN60 320-2-2 Standard Sheet F Class I
Max Operating Temperature:	+70°C
Min Operating Temperature:	-40°C
Max Panel Thickness:	1.5mm
Min Panel Thickness:	1.5mm
Number Of Contacts:	3 Contacts
Rohs Compliant:	Yes
Voltage Max:	250V

// Product PDF Links

[IEC Connectors product data](#)

// Product 3D CAD Model Links

[PX0783/15/633D CAD Model](#)