


Product Name // Mini Series Panel Mount 90 Degree Connector Body

[View Product Page](#)

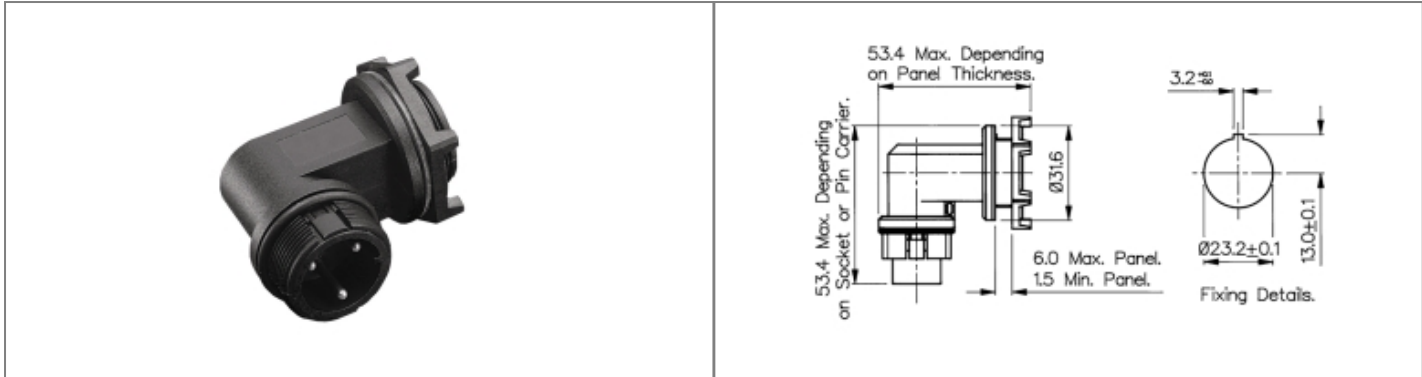

// Product Description:

- ⊕ Mini Series of modular connectors
- ⊕ Water and dustproof to IP68 when mated with compatible connector
- ⊕ Choose type of connector body:
- ⊕ Part codes prefixed PX0800 - Flex Cable Connectors (mate with PX0801 Inline Cable Connectors, PX08 Mini Series Panel Mount Connectors), optionally choose cable acceptance
- ⊕ Part codes prefixed PX0801 - Inline Cable Connectors (mate with PX0800 Flex Cable Connectors), optionally choose cable acceptance
- ⊕ Part codes prefixed PX0802, PX0803, PX0804, PX0805 - Panel Mount Connectors (mate with PX08 Mini Series Flex Cable Connectors)
- ⊕ Choose type of contacts from Screw Terminal, Solder/Crimp Contacts, BNC
- ⊕ Choose number of connector Contacts and select appropriate connector insert/contact carrier:
- ⊕ Screw Terminal inserts available separately in 2, 3, 4, 6 Contact, Pin or Socket
- ⊕ Solder, Crimp Contact carriers available separately in 3, 8 Contact; select appropriate Contact Pins or Sockets and Polarising/Blanking Pins, Contact Insertion Tool, Crimping Tool as required (all available separately)
- ⊕ BNC Plug or Socket insert available separately in 50 Ohm, 75 Ohm versions for all connector body styles except PX0803
- ⊕ PX0800, PX0801 Flex and Inline Cable Connector bodies have a choice of cable acceptance 3.5mm-9mm diameter depending on part code (see data for details)
- ⊕ Pack of Cable Glands for differing cable sizes also available separately (PX0812)
- ⊕ Sealing Caps (available separately) can be used to maintain IP rating of unmated connectors:
- ⊕ PX0811 fits PX0800 Flex Cable Connector
- ⊕ PX0810 fits all other connectors in the PX08 Mini Series

// General Information:

| | |
|--|--|
| Product Display Title: | Mini Series of modular connectors |
| Product Family: | Circular Power Connectors |
| Product Series: | Mini Buccaneer |
| Approvals: | UL |
| Body Material: | Polyamide (PA) |
| Body Material Type: | Plastic Body |
| Coupling Type: | Screw |
| Diameter Over Coupling Ring Mm: | 26mm |
| Flamability Rating: | UL94V-0 |
| Function: | Panel Mount Right Angle Connector Body |
| Ip Rating: | IP68 |
| Max Operating Temperature: | +70°C |
| Min Operating Temperature: | -20°C |

// Product PDF Links

- [Mini Series power connectors...](#)
- [Mini Series connectors wiring...](#)

// Product 3D CAD Model Links

- [PX08033D CAD Model](#)