
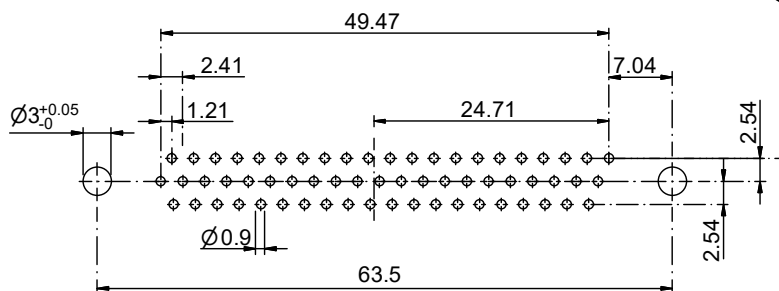
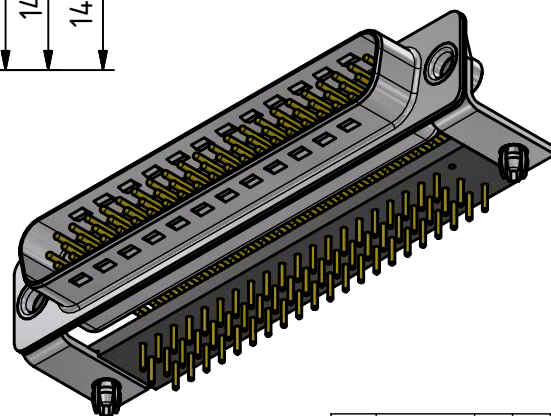
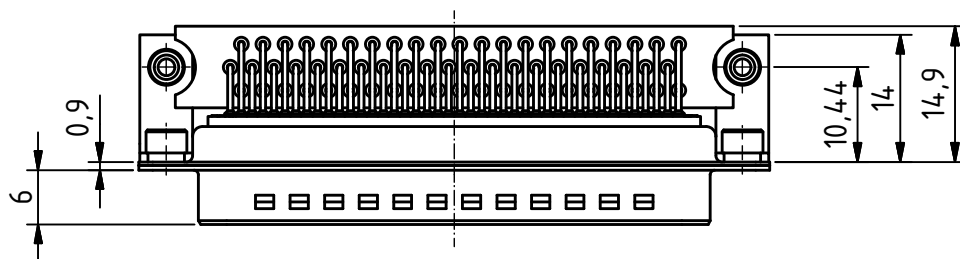
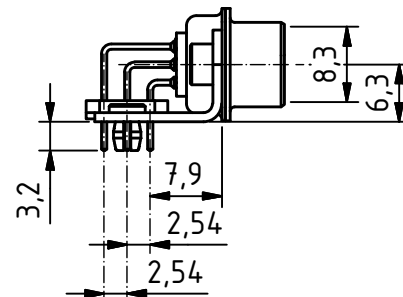


RoHS compliant

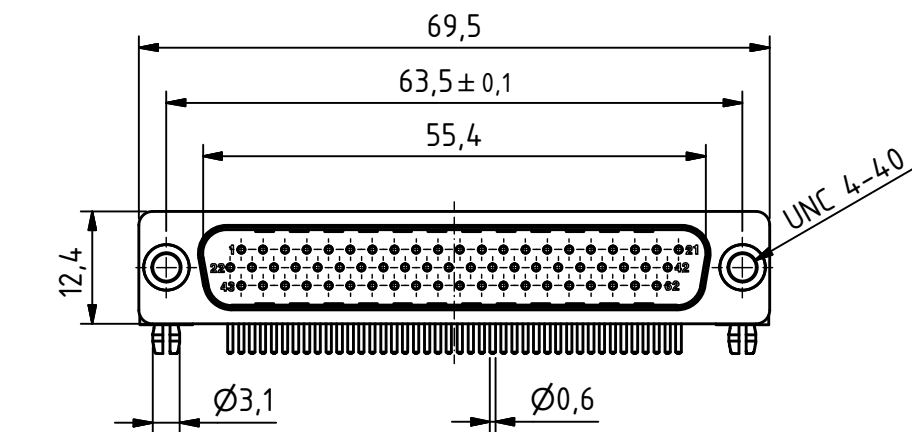

MATERIALS

- Insulator: Thermoplastic UL 94-V-0 white
- Contact: Machined / Copper alloy
- Contact finish: Quality class 2
- Shell: steel tin plated

CHARAKTERISTICS

- Working voltage: 60V
- Current rating: 5A
- Contact resistance: max. 10mΩ - DIN41652
- Insulation resistance: >5GΩ
- Temperature range: -55° to +125°C

General tolerances (Deltron standard)				
size in mm	tolerances			
	> 0.5 up to 3	> 3 up to 6	> 6 up to 30	> 30 up to 120
±0.1	±0.2	±0.2	±0.2	±0.3

modification	Rev.	Rev.	Rev.	DE009820		
	Rev.	Rev.	Rev.	part no.		
HD-D62PYC/2M47HUN	1.2:1 scale		drawn	29.09.2014	mr	
			checked			
			approved			
		Industrie NeuhoF 8c CH-3422 Kirchberg www.d-sub.swiss		K061786 drawing no.		