
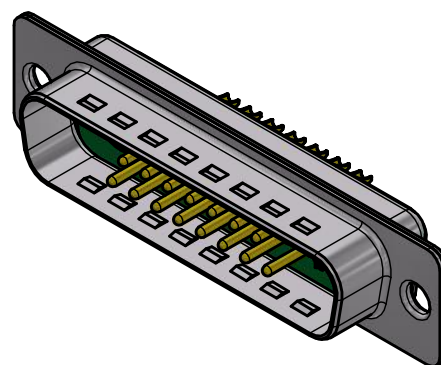
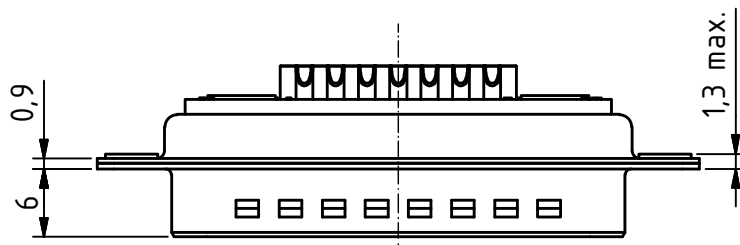
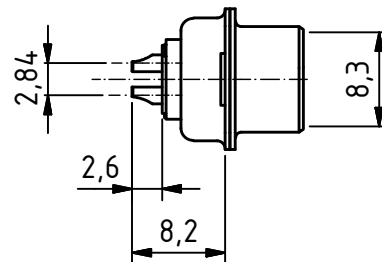


RoHS compliant

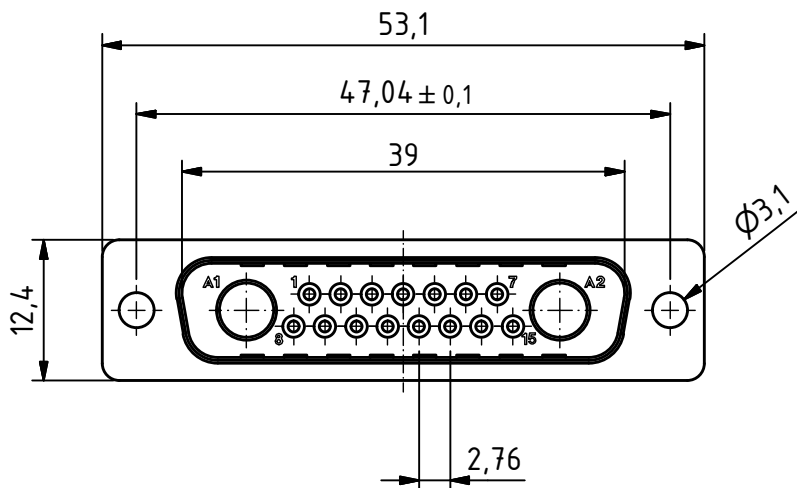

suitable for cable AWG 18

MATERIALS

- Insulator: Thermoplastic UL 94-V-0 green
- Contact: Machined / Copper alloy
- Contact finish: Quality class 2
- Shell: steel tin plated

CHARAKTERISTICS

- Working voltage: 125V
- Current rating: 7.5A/xxA
- Contact resistance: max. 10mΩ - DIN41652
- Insulation resistance: >5GΩ
- Temperature range: -55° to +125°C

General tolerances (Deltron standard)			
size in mm			
> 0.5	> 3	> 6	> 30
up to 3	up to 6	up to 30	up to 120
tolerances			
±0.1	±0.2	±0.2	±0.3

modification	Rev.	Rev.	Rev.	DE001951 part no.		
	Rev.	Rev.	Rev.			
DTS17W2PZ/2			1.5:1	drawn	27.06.2012	mw
			scale	checked		
				approved		
DELTRON CONNECT 2 CUSTOMIZE			Industrie Neuhof 8c CH-3422 Kirchberg www.d-sub.swiss			K051088 drawing no.