



Fixed Baseboard


- BaseBoard Size : 560 X 220 X 7mm
- WorkSpace : 205 X 118 mm

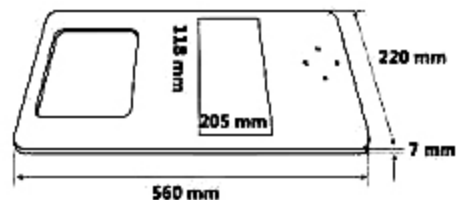

Industrial Camera Lens

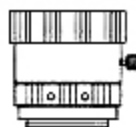


Pedestal of Extension Rod

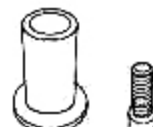

Camera Light Kit

- Power Adapter x1
- Lighting Source x1

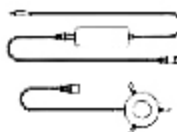


Building block


- Red Building block x10
- Yellow Building block x10
- Blue Building block x10
- Green Building block x10



 Extension Rod x2




H Ttype Camera Bracket

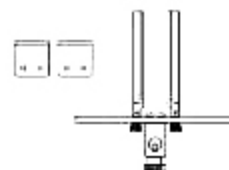

Black&White Calibration Board




Industrial Camera & USB

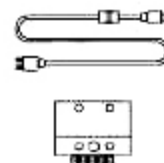

Tool Package

- Screw x 18
- Nut x 6
- Gasket x 6
- 2.5 / 5 / 6mm Wrench x 2

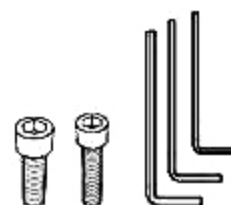

HD Color Industrial Camera	Product Number	JHSM300f
	Sensor Size	1/2'CMOS
	Sensor Type	MT9T001
	Effective Pixel	3 million
	Hue	colour
	Pixel Size	3.2x3.2um
	Frame Rate / Resolution	12 @2048x1536
	Filter	650nm
	SNR	42dB
	Dynamic range	61dB
	shutter type	Curtain exposure
	Time of exposure	50.8um- 3329ms
	Exposure control	auto/manual
	Size	40x45x45mm
	data interface	USB2.0
	working temperature	0 ~ 70°C

16mm Focus Lens	Type	M1614-MP2				
	focus	16mm				
	The maximum of the ratio of the diameter of lens to its focal length	1:1.4				
	Maximum image size	8.8mm×6.6mm(φ11mm)				
	Working range	aperture		F1.4-F16C		
		Focus point		0.3m-Inf		
	Control	aperture		Manual		
		Focus point		Manual		
	Object size	16.5(H)cm×12.4(V)cm 2/3 "				
	visual angle	D	38.0°			28.2°
		H	2/3 "	30.8°	1/2 "	22.7°
		V		23.4°		17.1°
	working temperature	-20°C-+50°C				
	Resolution rate	At the center and edge, more than100 (line /mm)				
	Deformation rate	2/3 "	-0.1%	1/2 "	-0.3%	
			(y=5.5)		(y=4.0)	
	Back focus	13.1mm				
	Length of flange lining	17.526mm				
	Fixing rack	C fixing rack				
	Filter size	M30.5P+0.5mm				
	Size	φ 33.5mm×28.2mm				
	Weight	65g				
	Operating distance (mm)	300	250	200	150	100
	Optical magnification	0.05 X	0.06 X	0.08 X	0.10 X	0.15 X
	Extension ring(mm)	Null	0.5	0.5	1.0	1.5

White auxiliary light source	Product number	JHZM-A40-W
	Luminous color	white
	LED number	48 LED
	illumination	40000lux
	brightness	Continuously adjustable, adjustable range ~100% Color temperature constant
	wavelength	455– 457.5nm
	output voltage	12 V
	output power	3.5 – 5 W
	Operating distance	35 – 110mm
	Size specification	internal diameter : 40mm,external diameter : 70mm,height : 25mm
	Outer diameter of lamp barrel	MaxΦ39mm
	Weight	0.48KG
	Working environment	temperature : 0 ~ 40°C , humidity : 20~85%RH
	Storage environment	temperature : -20 ~ 40°C , humidity : 20 ~85%RH