


R13-117

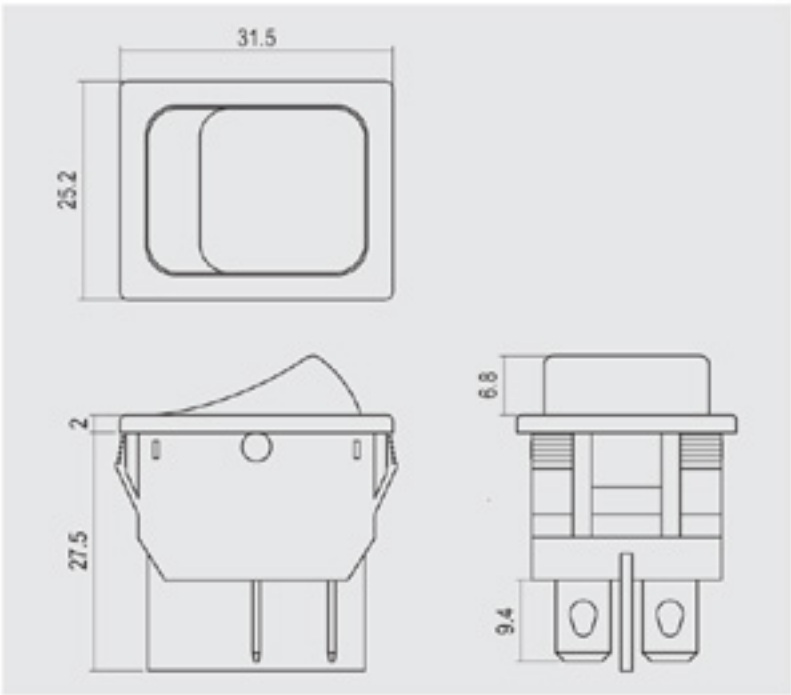

Rating
16A 125V AC 10A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1500V 1 minute
Cut-out

	X	Y
	X	Y
0.75~1.25	30.2±0.1	22.2±0.1
1.25~2	30.4±0.1	22.2±0.1
2~3	30.8±0.1	22.2±0.1

FEATURES

- * MATERIAL: Frames are nylon (UL flame: 94V-2). Terminals are silver plated brass.
- * Illuminated actuators are molded in PC, available with red, amber and green colors.
- * Snap-in mounting, easy to install switch into panel.

R13-117 -

	FUNCTION	TERMINAL
A	 4P DPST	0 1 .250" SQ
B	 4P DPST (ILLUMINATED) 125V AC 33K Ω / 250V AC 150K Ω	
C	 6P DPDT	
D	 6P DPDT	

