


PA1

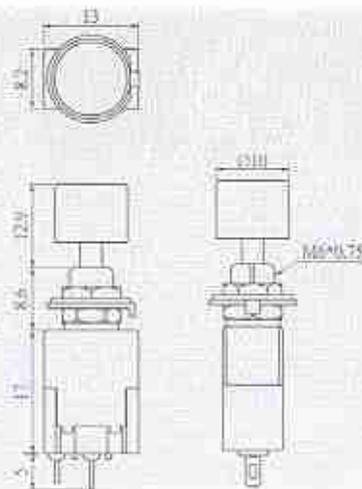

Rating

6A 125V AC
3A 250V AC

Contact resistance

50mΩ Max

Insulation resistant

DC 500V 100MΩ Min

Dielectric strength

AC 1000V 1 minute

Cut out



4 mm max

FEATURES

- * MATERIAL: Alkyd base (UL flame: 94V-0) for high insulation. Stainless steel cover for high corrosion resistant.
- * Contacts and Terminals are copper with silver alloy and silver plated.
- * Epoxy sealed for dust and moisture resistant.

PA1

FUNCTION	BUTTON	TERMINAL
<p>0 1</p> <p>ON OFF</p> <p>2P SPST</p>	<p>A</p>	<p>1 SO</p> <p>2 PC</p> <p>3 PC Angle(2.54)</p> <p>5 PC Angle(3.8)</p>
<p>0 2</p> <p>ON ON</p> <p>3P SPDT</p>		
<p>0 6</p> <p>ON (ON)</p> <p>3P SPDT</p>		

Druckschalter 6 A, PA 101/102

