



TP-Link TL-WPA4220 KIT PowerLine network adapter 300 Mbit/s Ethernet LAN Wi-Fi White 1 pc(s)



Brand : TP-Link

Product code: TL-WPA4220 KIT

Product name : TL-WPA4220 KIT

AV500 2-port Powerline WiFi Extender KIT, including 1 TL-WPA4220 and 1 TL-PA4010, 500Mbps Powerline data rate, 300Mbps wireless N, Plug and Play, 2 fast ethernet ports, WiFi Clone, Support Multiple IPTV Streams

TP-Link TL-WPA4220 KIT. Maximum data transfer rate: 300 Mbit/s, Networking standards: IEEE 802.11b, IEEE 802.11g, IEEE 802.11n, IEEE 802.3, IEEE 802.3u, Ethernet LAN interface type: Fast Ethernet. Power consumption (typical): 7.216 W, Power consumption (standby): 4.61 W, AC input voltage: 220 V. Product colour: White, Certification: CE, FCC. Windows operating systems supported: Windows 2000, Windows 2000 Professional, Windows 7 Enterprise, Windows 7 Enterprise x64, Windows 7.... Width: 94 mm, Depth: 54 mm, Height: 40 mm

Performance		System requirements	
Maximum data transfer rate *	300 Mbit/s	Windows operating systems supported	Windows 2000, Windows 2000 Professional, Windows 7 Enterprise, Windows 7 Enterprise x64, Windows 7 Home Basic, Windows 7 Home Basic x64, Windows 7 Home Premium, Windows 7 Home Premium x64, Windows 7 Professional, Windows 7 Professional x64, Windows 7 Starter, Windows 7 Starter x64, Windows 7 Ultimate, Windows 7 Ultimate x64, Windows 8, Windows 8 Enterprise, Windows 8 Enterprise x64, Windows 8 Pro, Windows 8 Pro x64, Windows 8 x64, Windows Vista Business, Windows Vista Business x64, Windows Vista Enterprise, Windows Vista Enterprise x64, Windows Vista Home Basic, Windows Vista Home Basic x64, Windows Vista Home Premium, Windows Vista Home Premium x64, Windows Vista Ultimate, Windows Vista Ultimate x64, Windows XP Home, Windows XP Home x64, Windows XP Professional, Windows XP Professional x64
Ethernet LAN *	✔		
Ethernet LAN interface type	Fast Ethernet		
Ethernet LAN data rates	10,100 Mbit/s		
Ethernet LAN (RJ-45) ports	2		
Wi-Fi *	✔		
Top Wi-Fi standard	Wi-Fi 4 (802.11n)		
Wi-Fi standards	802.11b, 802.11g, Wi-Fi 4 (802.11n)		
Networking standards *	IEEE 802.11b, IEEE 802.11g, IEEE 802.11n, IEEE 802.3, IEEE 802.3u		
Built-in power socket *	✘		
PowerLine standard	HomePlug AV		
Modulation	OFDM		
Security algorithms	64-bit WEP, 128-bit WEP, WPA, WPA-PSK, WPA2, WPA2-PSK		
Maximum operating distance	300 m		
Power		Linux operating systems supported	✔
Power consumption (typical)	7.216 W	Mac operating systems supported	✔
Power consumption (standby)	4.61 W	Operational conditions	
AC input voltage	220 V	Operating temperature (T-T)	0 - 40 °C
AC input frequency	50 Hz	Storage temperature (T-T)	-40 - 70 °C
Design		Operating relative humidity (H-H)	10 - 90%
LED indicators	✔	Storage relative humidity (H-H)	5 - 90%
Product colour *	White	Weight & dimensions	
Certification	CE, FCC	Width	94 mm
		Depth	54 mm
		Height	40 mm
		Certificates	
		Compliance certificates	RoHS
		Packaging content	
		Quantity per pack *	1 pc(s)
		Quick installation guide	✔
		Cables included	LAN (RJ-45)

Logistics data

Harmonized System (HS) code	85171800
-----------------------------	----------



5054230140765



8716065302172



8459730325792



0845973032579



845973032579




0132018352489



132018352489



5053086341531

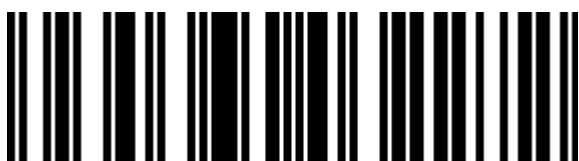

6935364032272



2273724024012



0758399147942



758399147942



4056203013138



5054629028612



5055851144118



5054063119600



5054230226506



5054484039198



5054533039193



5054063035375



7432408191135



8426232788677



0803982830449




803982830449



0172304354124




172304354124

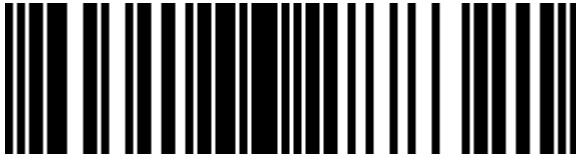

0809186288321




809186288321

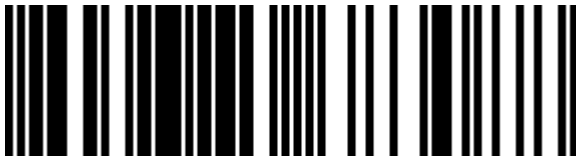

0809385683088



809385683088

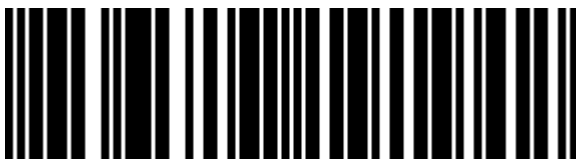

0856517191942



856517191942



0807030512493



807030512493



0163121537913




163121537913



0898029649511



898029649511

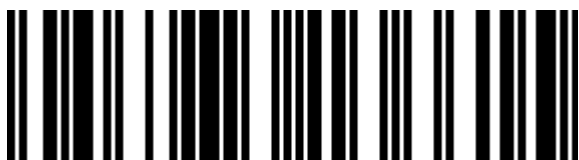

5053973136615




0809185831627



809185831627



6935364032074

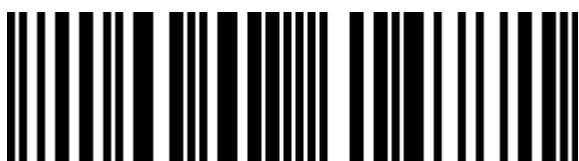

1210002614771

Catalog Object Cloud



Disclaimer: The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.