

StarTech.com Mini USB Bluetooth 4.0 Adapter - 50m (165ft) Class 1 EDR Wireless Dongle

Brand : StarTech.com

Product code: USBBT1EDR4

Product name : Mini USB Bluetooth 4.0 Adapter - 50m (165ft) Class 1 EDR Wireless Dongle

StarTech.com Bluetooth Adapter - Mini Bluetooth 4.0 USB Adapter - 50m/165ft Wireless Bluetooth Dongle - Smart Ready LE+EDR (USBBT1EDR4)
StarTech.com Mini USB Bluetooth 4.0 Adapter - 50m (165ft) Class 1 EDR Wireless Dongle. Connectivity technology: Wireless, Host interface: USB, Interface: Bluetooth. Maximum data transfer rate: 3 Mbit/s, Wi-Fi band: Single-band (2.4 GHz). Product colour: Black



Ports & interfaces		Operational conditions	
Connectivity technology *	Wireless	Storage temperature (T-T)	-20 - 70 °C
Host interface *	USB	Operating relative humidity (H-H)	0 - 75%
Interface *	Bluetooth	Sustainability	
Network		Sustainability compliance	✓
Maximum data transfer rate *	3 Mbit/s	Weight & dimensions	
Wi-Fi band	Single-band (2.4 GHz)	Width	14.4 mm
Frequency range	2.402 - 2.48 GHz	Depth	21.9 mm
Modulation	DQPSK, GFSK	Height	8 mm
Maximum operating distance	50 m	Weight	2 g
Bluetooth	✓	Packaging data	
Bluetooth version	4.0+EDR	Package width	173 mm
Design		Package depth	134 mm
Product colour	Black	Package height	33 mm
Internal *	✗	Package weight	56 g
Chipset	CSR8510A10	Packaging content	
LED indicators	Link, Power, Stand-by	Manual	✓
		Technical details	
		Compliance certificates	CE, RoHS
		Logistics data	
		Harmonized System (HS) code	85176990
		Master (outer) case width	309 mm
		Master (outer) case length	490 mm
		Master (outer) case height	426 mm
		Products per master (outer) case	60 pc(s)

System requirements

Windows operating systems supported	Windows 10, Windows 10 Education, Windows 10 Education x64, Windows 10 Enterprise, Windows 10 Enterprise x64, Windows 10 Home, Windows 10 Home x64, Windows 10 IOT Core, Windows 10 Pro, Windows 10 Pro x64, Windows 10 x64, Windows 11, Windows 11 x64, Windows 2000, Windows 2000 Professional, Windows 7, Windows 7 Enterprise, Windows 7 Enterprise x64, Windows 7 Home Basic, Windows 7 Home Basic x64, Windows 7 Home Premium, Windows 7 Home Premium x64, Windows 7 Professional, Windows 7 Professional x64, Windows 7 Starter, Windows 7 Starter x64, Windows 7 Ultimate, Windows 7 Ultimate x64, Windows 7 x64, Windows 8, Windows 8 Enterprise, Windows 8 Enterprise x64, Windows 8 Pro, Windows 8 Pro x64, Windows 8 x64, Windows 8.1, Windows 8.1 Enterprise, Windows 8.1 Enterprise x64, Windows 8.1 Pro, Windows 8.1 Pro x64, Windows 8.1 x64, Windows Vista Business, Windows Vista Business x64, Windows Vista Enterprise, Windows Vista Enterprise x64, Windows Vista Home Basic, Windows Vista Home Basic x64, Windows Vista Home Premium, Windows Vista Home Premium x64, Windows Vista Ultimate, Windows Vista Ultimate x64, Windows Vista x64, Windows XP, Windows XP Home, Windows XP Home x64, Windows XP Professional, Windows XP Professional x64
Mac operating systems supported	Mac OS 9.0, Mac OS 9.1, Mac OS 9.2, Mac OS X 10.10 Yosemite, Mac OS X 10.11 El Capitan, Mac OS X 10.12 Sierra, Mac OS X 10.13 High Sierra, Mac OS X 10.14 Mojave, Mac OS X 10.15 Catalina, Mac OS X 10.6 Snow Leopard, Mac OS X 10.7 Lion, Mac OS X 10.8 Mountain Lion, Mac OS X 10.9 Mavericks, Mac OS X 11.0 Big Sur, Mac OS X 12.0 Monterey, Mac OS X 13.0 Ventura
Server operating systems supported	Windows Server 2003, Windows Server 2008 R2, Windows Server 2012, Windows Server 2016, Windows Server 2019

Operational conditions

Operating temperature (T-T)	-10 - 50 °C
-----------------------------	-------------



0065030852920




065030852920



0758399150201



758399150201

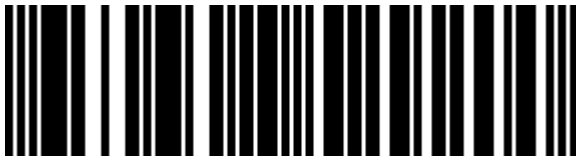

0650308529200



650308529200

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.