

StarTech.com 8 Port 1U Rackmount USB KVM Switch with OSD

Brand : StarTech.com

Product code: SV831DUSB

Product name : 8 Port 1U Rackmount USB KVM Switch with OSD



8 Port 1U Rackmount USB KVM Switch with OSD

StarTech.com 8 Port 1U Rackmount USB KVM Switch with OSD. Keyboard port type: USB, Mouse port type: USB, Video port type: VGA. Maximum resolution: 1920 x 1440 pixels. Product colour: Black, Rack capacity: 1U, Housing material: Steel. Input voltage: 100 - 240 V, Input current: 0.8 A, Output voltage: 12 V. Compliance certificates: RoHS



Ports & interfaces		Power	
Number of computers controlled *	8	Power plug type	Type M
Keyboard port type *	USB	Compatible power plug types	EU, UK, US
Mouse port type *	USB	Sustainability	
Video port type *	VGA	Compliance certificates	RoHS
VGA (D-Sub) ports quantity	9	Operational conditions	
Console ports *	USB A, VGA (D-Sub)	Operating temperature (T-T)	5 - 40 °C
Console USB ports quantity	2	Storage temperature (T-T)	-20 - 60 °C
Audio connections	✗	Operating relative humidity (H-H)	0 - 80%
DC-in jack	✓	Weight & dimensions	
Performance		Width	540 mm
Maximum resolution *	1920 x 1440 pixels	Depth	180 mm
Plug and Play	✓	Height	45 mm
Daisy chain	✓	Weight	2.9 kg
Design		Packaging data	
Rack mounting *	✓	Package width	89 mm
Rack capacity	1U	Package depth	573 mm
Product colour *	Black	Package height	268 mm
Housing material	Steel	Package weight	3.3 kg
LED indicators	✓	Packaging content	
Mean time between failures (MTBF)	150000 h	Manual	✓
Certification	CE, FCC, TAA, REACH	AC adapter included	✓
Display		Rubber feet	✓
Built-in display *	✗	Other features	
On Screen Display (OSD)	✓	Connectivity technology	Wired
Power		Dimensions (WxDxH)	540 x 180 x 45 mm
Input voltage	100 - 240 V	Ports quantity	8


Power		Other features	
Input current	0.8 A	Power requirements	110 - 240 AC
Output voltage	12 V	Audio support	×
Output current	1.5 A	IP control	×
Logistics data			
		Harmonized System (HS) code	85176200



0065030837255




065030837255

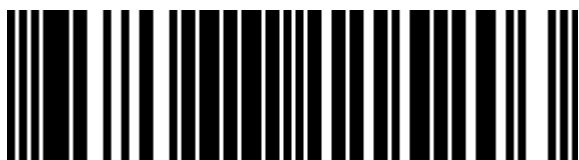

0652977115203



652977115203

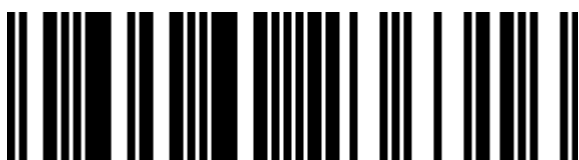

0069060236316



069060236316

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.