

StarTech.com 3 ft Shielded External eSATA Cable M/M

Brand : StarTech.comProduct code: ESATA3

Product name : 3 ft Shielded External eSATA Cable M/M

StarTech.com 3 ft Shielded External eSATA Cable M/M - 91cm eSATA to eSATA

StarTech.com 3 ft Shielded External eSATA Cable M/M:

Connect your external SATA storage devices to your Laptop or desktop.

This shielded eSATA cable offers a high quality 3ft connection between a desktop or laptop computer and external SATA storage devices, allowing you to "externalize" the impressive capabilities offered by Serial ATA.

The StarTech.com Advantage

- Up to six times faster than contemporary external storage solutions: USB 2.0 and Firewire (IEEE 1394)
- Robust and user friendly external connection
- High performance, cost effective expansion

StarTech.com 3 ft Shielded External eSATA Cable M/M. Cable length: 0.9 m, Cable type: eSATA, Connector 1: eSATA. Compliance certificates: RoHS, Certification: CE, REACH. Quantity per pack: 1 pc(s), Package width: 125 mm, Package depth: 225 mm




Features		Certificates	
Cable length *	0.9 m	Compliance certificates	RoHS
Cable type *	eSATA	Certification	CE, REACH
Connector 1 *	eSATA	Packaging data	
Connector 2 *	eSATA	Quantity per pack	1 pc(s)
Connector 1 form factor	Straight	Package width	125 mm
Connector 2 form factor	Straight	Package depth	225 mm
Connector gender *	Male/Male	Package height	16 mm
Product colour *	Black	Package weight	71 g
Maximum data transfer rate	6 Gbit/s	Logistics data	
Weight	66 g	Harmonized System (HS) code	84733080



0065030818469



065030818469

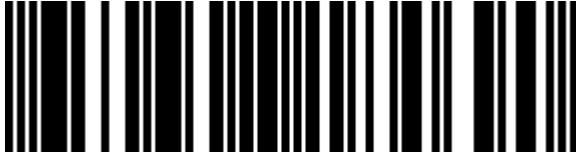

0650308184690



650308184690

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.