

StarTech.com 50x10mm Replacement Ball Bearing Computer Case Fan TX3/LP4 Connector

Brand : StarTech.com

Product code: FAN5X1TX3

Product name : 50x10mm Replacement Ball Bearing Computer Case Fan TX3/LP4 Connector



StarTech.com 50x10mm Replacement Ball Bearing Computer Case Fan TX3/LP4 Connector - 3 pin case Fan - TX3 Fan - 50mm Fan

StarTech.com 50x10mm Replacement Ball Bearing Computer Case Fan TX3/LP4 Connector:

Add additional chassis cooling with a 50mm ball bearing fan

This versatile 5cm x 1cm fan is an ideal replacement fan for keeping your computer running cool. The fan can be powered through a TX3 connection, and features a dual ball bearing design that ensures reliable cooling and longer fan lifespan.

The StarTech.com Advantage

- Exhausts hot air out of a PC, increasing dependability and extending component lifetime
- Cools your PC, increasing dependability and extending component lifetime
- Comes complete with a TX3 to LP4 adapter

StarTech.com 50x10mm Replacement Ball Bearing Computer Case Fan TX3/LP4 Connector. Type: Fan, Fan diameter: 5 cm, Rotational speed (max): 4500 RPM, Bearing type: Ball bearing. Voltage: 12 V. Width: 10 mm, Depth: 50 mm, Height: 50 mm. Product colour: Black



Performance		Power	
Suitable location *	Computer case	Power consumption (typical)	1.08 W
Type *	Fan	Voltage	12 V
Fan diameter	5 cm	Rated current	0.09 A
Rotational speed (max)	4500 RPM	Weight & dimensions	
Noise level (high speed)	23 dB	Width	10 mm
Maximum airflow	8.63 cfm	Depth	50 mm
Bearing type	Ball bearing	Height	50 mm
Mean time between failures (MTBF)	50000 h	Weight	19 g
Operating temperature (T-T)	-10 - 80 °C	Package width	66 mm
Design		Package depth	115 mm
Product colour *	Black	Package height	33 mm
Material	Plastic	Package weight	1 kg
Number of fans	1 fan(s)	Technical details	
Fan connector	3-pin	Compliance certificates	RoHS
Certification	CE, UR, UL, REACH	Logistics data	
		Harmonized System (HS) code	84733080




0065030786362



065030786362



6741523480088

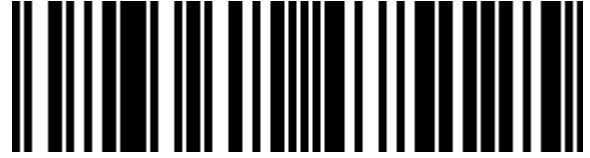

0023942475125



023942475125

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.