



DELL 403-BBMF interface cards/adapter Internal Fiber

Brand : DELL

Product code: 403-BBMF

Product name : 403-BBMF

Emulex LPe31002-M6-D, 16Gb Fibre Channel HBA, PCI Express 3.0 x8, 14.025 Gbps

DELL 403-BBMF interface cards/adapter Internal Fiber:

The Emulex LPe31002-M6-D Host Bus Adapter from Dell™ offers an exceptional performance and advanced management functionality that can shave days off installing and managing adapters. It is coupled with up to 2x better IOPS performance per watt, which makes Dell 16GB Fibre Channel (16GFC) host bus adapters the clear choice for the toughest virtualized, cloud and mission critical deployments.

- Doubling the maximum FC link rate 16GFC and enhanced virtualization capabilities help support IT "green" initiatives
- Frame-level multiplexing\increases link efficiency and maximizes HBA performance
- Accelerates network access to SSDs with NVMe over Fiber Channel ready feature- supports the upcoming NVMe over FC T11 standard

Ports & interfaces		Technical details	
Host interface *	PCIe	Compliance certificates	RoHS
Output interface *	Fiber	Packaging data	
Expansion card standard	PCIe 3.0	Quantity	1
Design		Logistics data	
Internal *	✓	Harmonized System (HS) code	84733020
Product colour	Green	Other features	
Purpose	Server	Data transfer rate	14.025 Mbit/s
Certification	CSA, UL, FCC, RoHS, TUV Bauart, BSMI Class A, ICES Class A, VCCI Class A, MSIP Class A, China RoHS, RCM	Ports quantity	2
		Data link protocols	16Gb Fibre Channel
		Connectivity technology	Wired
		Compatible operating systems	SUSE Linux Enterprise Server, Microsoft Windows, Red Hat Enterprise Linux
Operational conditions		- PowerEdge R630 - PowerEdge R730 - PowerEdge T630 - PowerEdge R730XD - PowerEdge R530 - PowerEdge R930 - PowerEdge R640 - PowerEdge R740 - PowerEdge R940 - PowerEdge R740XD - PowerEdge R440 - PowerEdge T640 - PowerEdge R540 - PowerEdge R7415 - PowerEdge R7425 - PowerEdge R840 - PowerEdge R940xa - PowerVault ME4012 - PowerVault ME4024 - PowerVault ME4084 - PowerEdge R7515 - PowerEdge R7525	
Operating temperature (T-T)	0 - 55 °C	Compatibility	
Operating relative humidity (H-H)	5 - 95%		
System requirements			
Windows operating systems supported	✓		
Linux operating systems supported	✓		






5397063979936



5711783355472

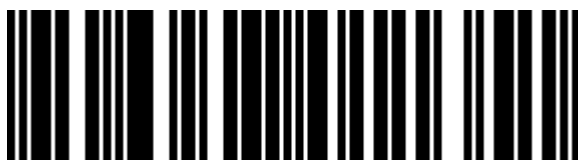

0706947011351



706947011351

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.