



APC Symmetra LX 16kVA N+1 uninterruptible power supply (UPS) 11200 W 1 AC outlet(s)

Brand : APC

Product code: SYAF16KI

Product name : Symmetra LX 16kVA N+1

Symmetra LX 16kVA N+1, 16 kVA, 11.2 kW, 62 dB, 116.36 kg, Black/Silver

[APC Symmetra LX 16kVA N+1 uninterruptible power supply \(UPS\) 11200 W 1 AC outlet\(s\):](#)

APC Symmetra, 11.2 kW / 16 kVA, Input 230V, 400V 3PH / Output 230V , Interface Port DB-9 RS-232, Smart-Slot

Includes: CD with software, Documentation CD, Installation guide, User Manual, Web/SNMP Management Card

Standard Lead Time: Usually in Stock


APC Symmetra LX 16kVA N+1. Output power capacity: 16 kVA, Output power: 11200 W, Input operation voltage (min): 155 V. AC outlets quantity: 1 AC outlet(s). Battery technology: Sealed Lead Acid (VRLA). Form factor: Tower. Safety: C-tick, CE, EN 50091-1, EN 50091-2, EN 55022 Class A, EN 55024, EN 60950, GOST, IEC 60950, VDE



Features		Design	
Output power capacity *	16 kVA	Form factor *	Tower
Output power *	11200 W	Operational conditions	
Input operation voltage (min) *	155 V	Operating temperature (T-T)	0 - 40 °C
Input operation voltage (max) *	480 V	Storage temperature (T-T)	-15 - 45 °C
Input frequency *	50/60 Hz	Operating relative humidity (H-H)	0 - 95%
Output operation voltage (min)	220 V	Storage relative humidity (H-H)	0 - 95%
Output operation voltage (max)	240 V	Operating altitude	0 - 3000 m
Efficiency	90%	Non-operating altitude	0 - 4500 m
Crest factor	5:1	Safety regulation & standards	
Emergency Power Off (EPO)	✓	Safety	C-tick, CE, EN 50091-1, EN 50091-2, EN 55022 Class A, EN 55024, EN 60950, GOST, IEC 60950, VDE
Output voltage Total Harmonic Distortion (THD)	5%	Weight & dimensions	
Noise level	62 dB	Width	483 mm
Audible alarm(s)	✓	Depth	726 mm
Ports & interfaces		Height	937 mm
AC outlets quantity	1 AC outlet(s)	Weight	116.4 kg
RS-232 ports	1	Packaging data	
Battery		Package weight	147.7 kg
Battery technology	Sealed Lead Acid (VRLA)	Other features	
		Battery type	SYBT5
		Dimensions (WxDxH)	483 x 726 x 937 mm
		Nominal output voltage	230 V

Other features

Nominal input voltage	230-400 V
Package dimensions (WxDxH)	599 x 997 x 1181 mm

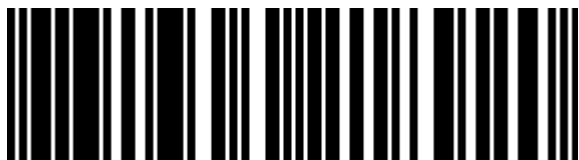

0731304218920



731304218920

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.