



Canon PGI-29CO Clear Ink Cartridge (Chroma Optimiser)

Brand : CanonProduct code: 4879B001

Product name : PGI-29CO Clear Ink Cartridge (Chroma Optimiser)

- Genuine Canon Ink produces on average 35% more quality prints than imitation cartridges†††
 - Genuine Canon Ink provides consistent quality prints 100% of the time†††
 - Genuine Canon Ink is 100% reliable so you can print with less stress†††
 - Return every ink and toner cartridge to be reused or recycled. It's free, easy and environmentally friendly.
- PGI-29CO Clear Ink Cartridge (Chroma Optimiser)

Canon PGI-29CO Clear Ink Cartridge (Chroma Optimiser):

The Chroma Optimizer clear ink from the professional LUCIA ink range delivers uniform glossiness, expands colour gamut and makes the black colours deeper. This pigment-based clear ink is applied on top of the colour inks. The 36ml ink tank allows you to print up to 429 photos in 10x15cm or 90 in A3+ size at ISO/JIS-SCID† standard.

Canon PGI-29CO Clear Ink Cartridge (Chroma Optimiser). Colour ink page yield: 429 pages, Printing colours: Transparent, Quantity per pack: 1 pc(s)

Features		Operational conditions	
Print technology	Inkjet printing	Operating relative humidity (H-H)	15 - 90%
Compatibility *	PIXMA PRO-1	Storage temperature (T-T)	-40 - 60 °C
Quantity per pack *	1 pc(s)	Operating temperature (T-T)	5 - 35 °C
Colour ink page yield *	429 pages	Storage relative humidity (H-H)	15 - 90%
Type *	Original	Packaging data	
Printing colours *	Transparent	Package type	Blister
Country of origin	Japan	Logistics data	
		Harmonized System (HS) code	84439990





4053162253919




5053973868400




4960999682105



5052883252774

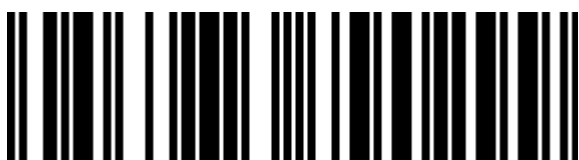

5053973790299

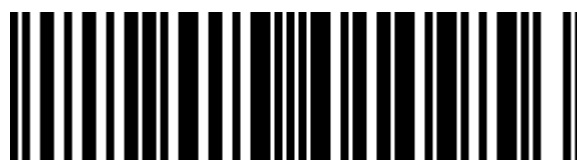

2112014010956

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.