



Jabra LINK 14201-31

Brand : Jabra

Product code: 14201-31

Product name : LINK 14201-31

- MPN: 14201-31
 - Original and authentic, manufacturer made accessory.
 - The Jabra LINK™ 14201-31 enables remote Electronic Hook Switch Control (EHS) with Jabra wireless headsets and the NEC DT730 IP Phones.
- LINK 14201-31

Jabra LINK 14201-31:

Enjoy wireless freedom and get remote call control on your wireless headset from a wide range of NEC deskphones using an Electronic Hook Switch (EHS) cord. Answer or end calls, mute the microphone and adjust volume when you are away from the desk.


The Jabra LINK™ 14201-31 enables remote Electronic Hook Switch Control (EHS) with Jabra wireless headsets and the NEC DT730 IP Phones.

Electronic hook switch solution for NEC phones. Jabra LINK 14201-31 enables remote Electronic Hook Switch Control (EHS) with Jabra PRO wireless headset series and the NEC DT730 IP phones. Once installed, employees can control their call directly from their Jabra wireless headsets up to 450 ft away from their desk.

Jabra LINK 14201-31. Product type: EHS adapter, Product colour: Black




Features		Packaging content	
Product type *	EHS adapter	Quantity per pack	1 pc(s)
Brand compatibility *	Jabra	Packaging data	
Compatibility	GN 9120 DHSG, GN 93XX, PRO 94XX, PRO 920, GO 6470 NEC DT730 & 750	Package width	160 mm
Product colour	Black	Package depth	25 mm
Electronic hook switch (EHS)	✓	Package height	210 mm
		Package weight	50 g
Weight & dimensions		Logistics data	
Cable length	0.9 m	Harmonized System (HS) code	85189000
Ports & interfaces		Products per master (outer) case	100 pc(s)
Bluetooth	✓	Country of origin	China

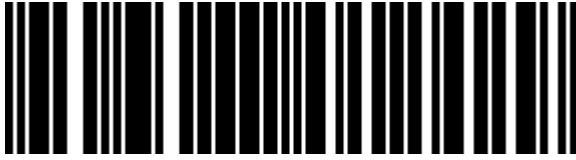

0706487012429



706487012429

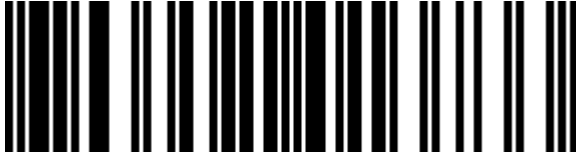

5706991013733

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.