

Brother LC223M ink cartridge 1 pc(s) Original Magenta

Brand : Brother

Product code: LC223M

Product name : LC223M


- LC223M Prints 550 pages in accordance with ISO/IEC 24711.
 - High quality genuine Brother magenta ink cartridge.
 - Genuine Brother ink cartridges are rigorously tested to print perfectly every time saving you time and money.
 - Using this Brother LC223M original ink cartridge protects your printer warranty.
 - The LC223 range of ink cartridges are available as a more economical value pack, reducing your cost per page - LC223VALBP
- The Brother LC223M Magenta Ink Cartridge – Single Pack. Prints 550 pages.

Brother LC223M ink cartridge 1 pc(s) Original Magenta:

Brother consider the environmental impact at every stage of your ink cartridge life cycle, reducing waste at landfill. All our hardware and ink cartridges are built to have as little impact on the environment as possible. Genuine Brother LC223M ink cartridge - worth it every time
 Brother LC223M. Colour ink type: Pigment-based ink, Supply type: Single pack, Colour ink page yield: 550 pages, Printing colours: Magenta, Quantity per pack: 1 pc(s)



Features		Packaging data	
Colour ink type	Pigment-based ink	Package depth	130 mm
Print technology	Inkjet printing	Package height	26 mm
Compatibility *	Brother MFC-J4420DW, MFC-J4625DW	Package weight	40 g
Quantity per pack *	1 pc(s)	Package type	Blister
Colour ink page yield *	550 pages	Other features	
Type *	Original	Page yield footnote	ISO / IEC 24711
Ink type	Pigment-based ink	Paper dimensions	A4
Printing colours *	Magenta	Logistics data	
Brand compatibility *	Brother	Pallet gross height	15 cm
Supply type *	Single pack	Products per pallet	3000 pc(s)
Country of origin	Philippines	Master (outer) cases per pallet	30 pc(s)
Weight & dimensions		Layers per pallet	5 pc(s)
Width	25 mm	Master (outer) cases per pallet layer	6 pc(s)
Depth	91 mm	Pallet gross weight	192 kg
Height	116 mm	Harmonized System (HS) code	84439990
Weight	34 g	Pallet type	800 x 1200 mm
Packaging data			
Package width	91 mm		

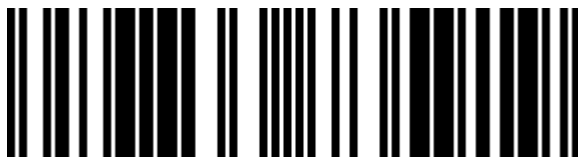

4977766735919



5715328103061

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.