


Epson Premium Glossy Photo Paper - A4 - 20 Sheets

Brand : Epson

Product code: C13S041287

Product name : Premium Glossy Photo Paper - A4 - 20 Sheets

Premium Glossy Photo Paper - A4 - 20 Sheets
Epson Premium Glossy Photo Paper - A4 - 20 Sheets. Finish type: Premium-gloss, Media weight: 255 g/m², Paper size: A4. Width: 210 mm, Height: 297 mm, Roll width: 21 cm. Quantity per pack: 1 pc(s), Package width: 230 mm, Package depth: 340 mm. Pallet width (UK): 100 cm, Pallet length (UK): 120 cm, Pallet height (UK): 120 cm. Country of origin: Japan

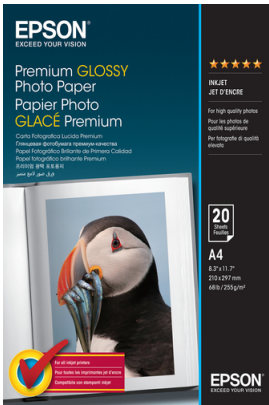

Features		Logistics data	
Paper size	A4	Pallet height (UK)	120 cm
Paper size	21x29.7 cm	Pallet weight (UK)	0 g
Product colour	White	Pallet gross width	80 cm
Finish type *	Premium-gloss	Pallet gross length	120 cm
Media weight *	255 g/m²	Pallet gross height	120 cm
Best uses	Brochure, Office printing, Calendar, Photo collage, Photo gifts, Photo, Cards and gift wraps, Seasonal decorations and gifts	Pallet gross weight	0 g
Sheets per pack	20 sheets	Products per pallet	1080 pc(s)
Weight & dimensions		Products per pallet (UK)	1440 pc(s)
Width	210 mm	Products per pallet layer	180 pc(s)
Height	297 mm	Products per pallet layer (UK)	240 pc(s)
Roll width	21 cm	Master (outer) case width	250 mm
Packaging data		Master (outer) case length	360 mm
Quantity per pack	1 pc(s)	Master (outer) case height	200 mm
Package width	230 mm	Master (outer) case gross weight	10 kg
Package depth	340 mm	Products per master (outer) case	20 pc(s)
Package height	4 mm	Minimum order quantity	20 pc(s)
Package weight	460 g	Other features	
Logistics data		Country of origin	Japan
Harmonized System (HS) code	37032000		
Pallet width (UK)	100 cm		
Pallet length (UK)	120 cm		



0010343819245



010343819245



8885007027326

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.