




Jabra LINK 14201-32

Brand : Jabra

Product code: 14201-32

Product name : LINK 14201-32

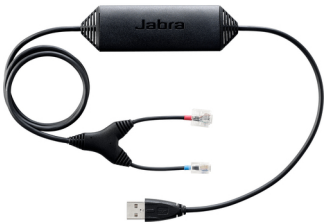

LINK 14201-32

Jabra LINK 14201-32:


Enjoy wireless freedom and get remote call control on your wireless headset from a wide range of Nortel/Avaya deskphones using an Electronic Hook Switch (EHS) cord. Answer or end calls, mute the microphone and adjust volume when you are away from the desk.

The Jabra LINK™ 14201-32 enables remote Electronic Hook Switch Control (EHS) with Jabra wireless headsets and the Nortel/Avaya 1100 Series IP Phones with USB headset port.

Electronic hook switch solution for Avaya/Nortel phones with USB headset port. Jabra LINK 14201-32 enables remote Electronic Hook Switch Control (EHS) with Jabra wireless headsets and the Avaya/Nortel 11 series IP Phones with USB headset port. Once installed, employees can control their call directly from their Jabra wireless headsets up to 450 ft away from their desk.

Jabra LINK 14201-32. Product type: EHS adapter, Product colour: Black


Features		Packaging data	
Product type *	EHS adapter	Package width	160 mm
Brand compatibility *	Avaya	Package depth	15 mm
Compatibility	Avaya/Nortel 11 series IP Phones, Jabra 9120 DHSG, GN 93XX, PRO 94XX, PRO 920, GO 6470	Package height	210 mm
		Package weight	50 g
Product colour	Black	Logistics data	
Electronic hook switch (EHS)	✓	Harmonized System (HS) code	85189000
Ports & interfaces		Products per master (outer) case	100 pc(s)
Connector 1	RJ-9	Country of origin	China
Connector 2	RJ-9		
Bluetooth	✓		

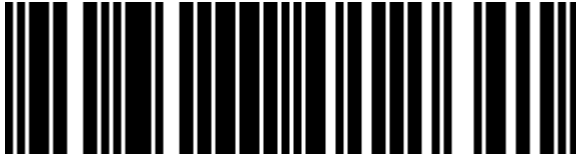

0706487012641



706487012641

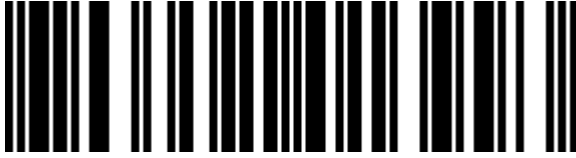

5706991013993

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.