



Lenovo ThinkSystem Broadcom 5719 Internal Ethernet 1000 Mbit/s

Brand : Lenovo

Product code: 7ZT7A00484

Product name : ThinkSystem Broadcom 5719



ThinkSystem Broadcom 5719 1GbE RJ45 4-Port PCIe Ethernet Adapter


Lenovo ThinkSystem Broadcom 5719 Internal Ethernet 1000 Mbit/s:

The Broadcom NetXtreme Gigabit Ethernet Adapters are a family of high performance PCIe and OCP adapters. The adapters are available with either two ports or four ports and are supported on ThinkSystem and System x servers.

This product guide provides essential presales information to understand the NetXtreme GbE offerings and their key features, specifications, and compatibility. This guide is intended for technical specialists, sales specialists, sales engineers, IT architects, and other IT professionals who want to learn more about the adapters and consider their use in IT solutions.

Lenovo ThinkSystem Broadcom 5719. Internal. Connectivity technology: Wired, Host interface: PCI Express, Interface: Ethernet. Maximum data transfer rate: 1000 Mbit/s

Ports & interfaces		Design	
Connectivity technology *	Wired	Component for *	Server/workstation
Host interface *	PCI Express	Internal *	✓
Interface *	Ethernet	Weight & dimensions	
Ethernet LAN (RJ-45) ports	4	Width	132 mm
Network		Depth	19 mm
Maximum data transfer rate *	1000 Mbit/s	Height	65 mm
Networking standards *	IEEE 802.1Q	Logistics data	
Ethernet LAN data rates	10,100,1000 Mbit/s	Harmonized System (HS) code	85176990

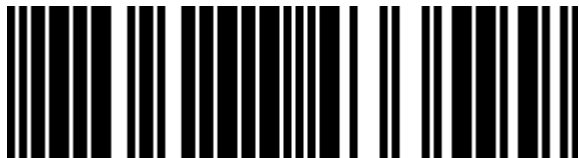

0889488433599



889488433599

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.