



APC Symmetra LX Extended Run Rackmount uninterruptible power supply (UPS)



Brand : APC

Product code: SYARMXR9B9I

Product name : Symmetra LX Extended Run Rackmount

APC Symmetra LX Extended Run Rack-mount

APC Symmetra LX Extended Run Rackmount uninterruptible power supply (UPS):

Modular design

Modular construction - can be deployed as a non-standby and migrate to a standby (UPS) system.

Hot-swappable batteries


Ensures clean, uninterrupted power to protected equipment while batteries are being replaced.

Battery modules connected in parallel

Delivers higher availability through redundant batteries.

APC Symmetra LX Extended Run Rackmount. Battery technology: Sealed Lead Acid (VRLA), Battery capacity: 7776 Ah, Battery voltage: 230 V. Form factor: Rackmount/Tower, Product colour: Black. Certification: BSMI, EN 50091-1, EN 50091-2, EN 60950, IEC 60950, VCCI, VDE. Weight: 312.7 kg. Package weight: 363.2 kg


Battery		Operational conditions	
Battery technology	Sealed Lead Acid (VRLA)	Operating altitude	0 - 3000 m
Battery capacity	7776 Ah	Certificates	
Battery voltage	230 V	Certification	BSMI, EN 50091-1, EN 50091-2, EN 60950, IEC 60950, VCCI, VDE
Design		Weight & dimensions	
Form factor *	Rackmount/Tower	Weight	312.7 kg
Product colour *	Black	Packaging data	
Operational conditions		Package weight	363.2 kg
Operating temperature (T-T)	0 - 40 °C	Logistics data	
Storage temperature (T-T)	-15 - 45 °C	Harmonized System (HS) code	85078000
Operating relative humidity (H-H)	0 - 95%	Other features	
Storage relative humidity (H-H)	0 - 95%	Dimensions (WxDxH)	483 x 786 x 572 mm
		Package dimensions (WxDxH)	599 x 997 x 797 mm

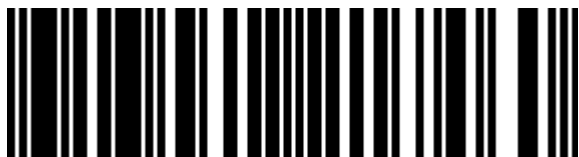

7313042217460



8592978056704

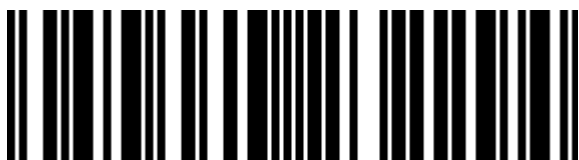

5054444232294

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.