

Brother LC-129XLVALBP ink cartridge 4 pc(s) Original Black, Cyan, Maroon, Yellow



Brand : Brother

Product code: LC129XLVALBP

Product name : LC-129XLVALBP

- Black cartridge prints 2,400 pages and each colour cartridges print 1,200 pages in accordance with ISO/IEC 24711
 - High quality genuine Brother cartridge
 - Prevents waste to save you paper, time and money
 - Genuine Brother ink cartridges are rigorously tested to print perfectly every time saving you time and money
 - Using Brother LC3219 original high yield ink cartridges protects your printer warranty
- The Brother LC129XLVALBP Black, Cyan, Magenta and Yellow Ink Cartridges Multipack. Each colour cartridge prints 1,200 pages; black cartridges prints 2,400 pages.

Brother LC-129XLVALBP ink cartridge 4 pc(s) Original Black, Cyan, Maroon, Yellow:

Purchase this value LC129XLVALBP multipack to save on genuine Brother cartridges. The high yield cartridges enable you to conveniently replace all of your ink for less so that your printer continues to deliver the best possible results.

Brother LC-129XLVALBP. Supply type: Multi pack, Colour ink page yield: 1200 pages, Printing colours: Black, Cyan, Maroon, Yellow, Quantity per pack: 4 pc(s), Black ink page yield: 2400 pages


Features		Weight & dimensions	
Compatibility *	MFC-J6520DW MFC-J6720DW MFC-J6920DW	Height	180 mm
Quantity per pack *	4 pc(s)	Weight	256 g
Black ink cartridges quantity	1	Packaging data	
Colour ink cartridges quantity	3	Package weight	301 g
Black ink page yield *	2400 pages	Package type	Blister
Colour ink page yield *	1200 pages	Logistics data	
Type *	Original	Pallet gross height	16.3 cm
Printing colours *	Black, Cyan, Maroon, Yellow	Products per pallet	544 pc(s)
Brand compatibility *	Brother	Master (outer) cases per pallet	136 pc(s)
Supply type *	Multi pack	Layers per pallet	8 pc(s)
Country of origin	China	Master (outer) cases per pallet layer	17 pc(s)
Weight & dimensions		Pallet gross weight	191.4 kg
Width	65 mm	Harmonized System (HS) code	84439990
Depth	215 mm	Pallet type	1200 x 1000 mm




3609740137464




5014047566707

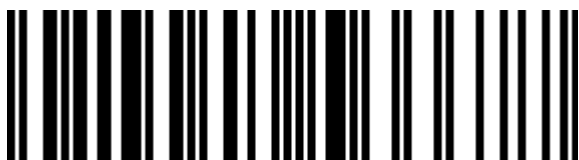

5014047566677

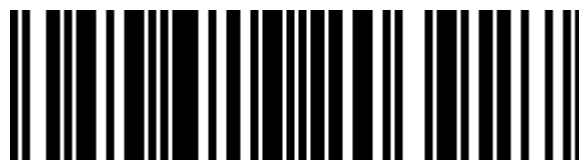


5054629203927

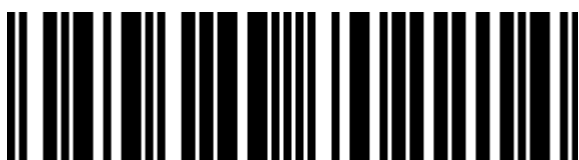

5054484702214



4056104662671

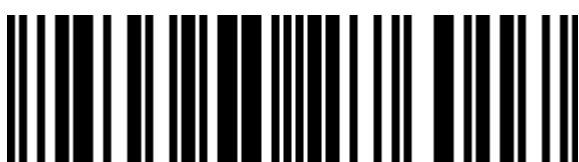

4250905276017




4056104657356



4056104727042



5054533702219

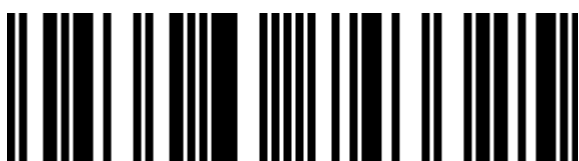

5056066743325

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.