




Lenovo TS2270 Storage drive Tape Cartridge LTO 6 TB

Brand : Lenovo
Product code: 6160S7E
Product name : TS2270



- Long-term tape storage for backup & archive
 - Easy access to data on LTO Ultrium 7/6/5 cartridges, through IBM® Spectrum Archive™ technology
 - Media-partitioning on LTO Ultrium 7 media
- IBM TS2270 Tape Drive, LTO Ultrium 7, 6Gbps SAS interface, 4.3kg
Lenovo TS2270. Product type: Storage drive, Media type: Tape Cartridge, Interface: Serial Attached SCSI (SAS). Native capacity: 6 TB, Compressed capacity: 15 TB. Maximum data transfer rate: 300 Mbit/s.
Width: 213 mm, Depth: 332 mm, Height: 58 mm. Quantity per pack: 1 pc(s)


Performance		Data transmission	
Product type *	Storage drive	Maximum data transfer rate	300 Mbit/s
Media type *	Tape Cartridge	Weight & dimensions	
Interface *	Serial Attached SCSI (SAS)	Width	213 mm
Data storage type	LTO	Depth	332 mm
Compression ratio *	2.5:1	Height	58 mm
Form factor	2U	Weight	4.3 kg
Product colour	Black	Packaging data	
Storage		Quantity per pack	1 pc(s)
Native capacity *	6 TB	Logistics data	
Compressed capacity *	15 TB	Harmonized System (HS) code	84719000

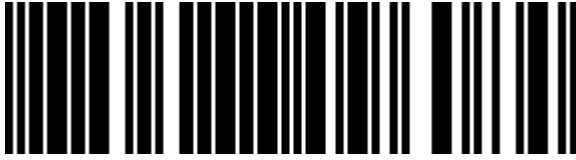

0889488096084



889488096084

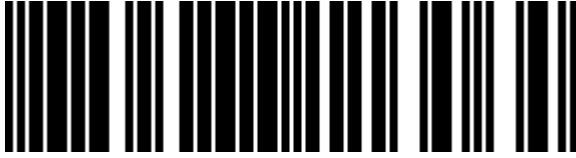

0889488113064



889488113064



8894881130640

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.