

StarTech.com KVM Console to USB 2.0 Portable Laptop Crash Cart Adapter

Brand : StarTech.com

Product code: NOTECONS01

Product name : KVM Console to USB 2.0 Portable Laptop Crash Cart Adapter



StarTech.com Crash Cart Adapter – 1920 x 1200 – Portable Laptop USB 2.0 to KVM Console (NOTECONS01)

StarTech.com KVM Console to USB 2.0 Portable Laptop Crash Cart Adapter. Keyboard port type: USB, Mouse port type: USB, Video port type: VGA. Compliance certificates: CE, RoHS. Weight: 170 g, Package width: 300 mm, Package depth: 45 mm. Compatible operating systems: Windows® XP, Vista, 7, 8, 8.1, 10, 11 Windows Server® 2008 R2, 2012, 2016, 2019 macOS 10.6 to.... Master (outer) case width: 320 mm, Master (outer) case length: 520 mm, Master (outer) case height: 525 mm



Performance		Packaging data	
Product colour	Black	Package depth	45 mm
Keyboard port type *	USB	Package height	160 mm
Mouse port type *	USB	Package weight	400 g
Video port type *	VGA	Other features	
Connector 1	USB Mini-B		
Connector 2	PS/2 + USB 2.0 A + VGA		
Connector 1 gender	Female		
Connector 2 gender	Male		
Certificates		Compatible operating systems Windows® XP, Vista, 7, 8, 8.1, 10, 11 Windows Server® 2008 R2, 2012, 2016, 2019 macOS 10.6 to 10.15, 11.0, 12.0, Mac OS X 13.0 Ventura Linux 2.6.x +	
Compliance certificates	CE, RoHS		
Sustainability			
Sustainability compliance	✔		
Packaging data			
Weight	170 g	Logistics data	
Package width	300 mm	Harmonized System (HS) code	84733080
		Master (outer) case width	320 mm
		Master (outer) case length	520 mm
		Master (outer) case height	525 mm
		Products per master (outer) case	30 pc(s)




0065030835312



065030835312



5051964712992

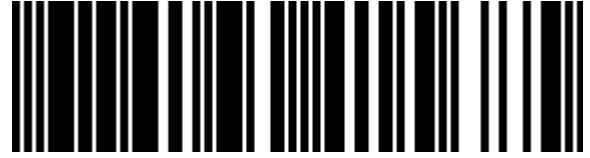

0686164415685



686164415685

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.