

Brother LC229XLBK ink cartridge 1 pc(s) Original Black

Brand : Brother

Product code: LC229XLBK

Product name : LC229XLBK

- Prints 2,400 pages in accordance with ISO/IEC 24711
 - High quality genuine Brother cartridge
 - Prevents waste to save you paper, time and money
 - Using this Brother LC229XLBK original high yield ink cartridge protects your printer warranty
 - The LC229XL / LC225XL range of ink cartridges are available as a more economical value pack, reducing your cost per page even further - LC229XLVALBP
- The Brother LC229XLBK Extra High Yield Black Ink Cartridge. Prints 2,400 pages

Brother LC229XLBK ink cartridge 1 pc(s) Original Black:

Over its 2,400 page lifespan, the LC229XLBK offers a consistently high quality trouble-free printing experience. With smudge-free, longer-lasting prints, this fade resistant extra high yield LC229XLBK has been developed using the newly formulated Innobella™ ink, making it very well-suited to a wide range of printing tasks.


Brother LC229XLBK. Black ink type: Pigment-based ink, Supply type: Single pack, Printing colours: Black, Quantity per pack: 1 pc(s), Black ink page yield: 2400 pages



Features		Packaging data	
Black ink type	Pigment-based ink	Package weight	140 g
Print technology	Inkjet printing	Package type	Blister
Compatibility *	Brother MFC-J5320DW, MFC-J5620DW, MFC-J5625DW, MFC-J5720DW	Other features	
Quantity per pack *	1 pc(s)	Page yield footnote	ISO / IEC 24711
Black ink page yield *	2400 pages	Paper dimensions	A4
Type *	Original	Logistics data	
Ink type	Pigment-based ink	Pallet gross height	17.2 cm
Printing colours *	Black	Products per pallet	2100 pc(s)
Brand compatibility *	Brother	Master (outer) cases per pallet	42 pc(s)
Supply type *	Single pack	Layers per pallet	6 pc(s)
Country of origin	Philippines	Master (outer) cases per pallet layer	7 pc(s)
Weight & dimensions		Pallet gross weight	317.9 kg
Width	38 mm	Harmonized System (HS) code	84439990
Depth	92 mm	Pallet type	800 x 1200 mm
Height	116 mm		
Weight	102 g		



5711783954903

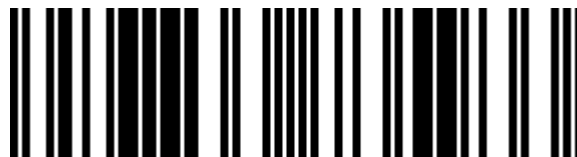

4977766735933

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.