

## Viewsonic X2000B-4K data projector Short throw projector 2000 ANSI lumens UHD 4K (3840x2160) 3D Black

**Brand :** Viewsonic

**Product code:** X2000B-4K

**Product name :** X2000B-4K

- True 4K HDR immersive visual experience
- 0.22 ultra short throw ratio capable of 100" screen from 23cm away
- 2nd generation Laser Phosphor technology with 20,000 hours lifespan
- Theater-level audio by Harman Kardon with Dolby/DTS support
- Smart connectivity via Wi-Fi and Bluetooth


4K HDR Ultra Short Throw Smart Laser Projector

Viewsonic X2000B-4K. Projector brightness: 2000 ANSI lumens, Projector native resolution: UHD 4K (3840x2160), Contrast ratio (typical): 3000000:1. Light source type: Laser, Service life of light source: 20000 h, Lamp type: Nichia. Zoom type: Fixed, Offset: 140%. Supported graphics resolutions: 640 x 480 (VGA), 3840 x 2160, Supported video modes: 480i, 480p, 576i, 576p, 720p, 1080i, 1080p, 2160p. Serial interface type: RJ-45, HDMI connector type: Full-size



| Projector                          |                                                   | Features                           |                                                                                                                                                                                                                                    |
|------------------------------------|---------------------------------------------------|------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Smart projector *                  | ✓                                                 | On Screen Display (OSD)            | ✓                                                                                                                                                                                                                                  |
| Screen size compatibility *        | 2540 - 2540 mm (100 - 100")                       | On Screen Display (OSD) languages  | Arabic, Simplified Chinese, Traditional Chinese, Czech, German, Dutch, English, Spanish, Finnish, French, Greek, Hungarian, Indonesian, Italian, Japanese, Korean, Polish, Portuguese, Russian, Swedish, Thai, Turkish, Vietnamese |
| Projection distance                | 0.082 - 0.52 m                                    |                                    |                                                                                                                                                                                                                                    |
| Projector brightness *             | 2000 ANSI lumens                                  | Number of OSD languages            | 24                                                                                                                                                                                                                                 |
| Projector native resolution *      | UHD 4K (3840x2160)                                | Screen mirroring                   | ✓                                                                                                                                                                                                                                  |
| Contrast ratio (typical) *         | 3000000:1                                         | Noise level *                      | 32 dB                                                                                                                                                                                                                              |
| Native aspect ratio *              | 16:9                                              | Real cinema                        | ✓                                                                                                                                                                                                                                  |
| Number of colours                  | 1.07 billion colours                              | High Dynamic Range (HDR) supported | ✓                                                                                                                                                                                                                                  |
| Vertical scan range                | 23 - 120 Hz                                       | Eye protection                     | ✓                                                                                                                                                                                                                                  |
| Light source                       |                                                   | Multimedia                         |                                                                                                                                                                                                                                    |
| Light source type *                | Laser                                             | Built-in speaker(s) *              | ✓                                                                                                                                                                                                                                  |
| Service life of light source *     | 20000 h                                           | RMS rated power                    | 50 W                                                                                                                                                                                                                               |
| Lamp type                          | Nichia                                            | Number of built-in speakers        | 2                                                                                                                                                                                                                                  |
| Lamp power                         | 74 W                                              | Design                             |                                                                                                                                                                                                                                    |
| Lamps quantity                     | 1 lamp(s)                                         | Market positioning *               | Home cinema                                                                                                                                                                                                                        |
| Lens system                        |                                                   | Product type *                     | Short throw projector                                                                                                                                                                                                              |
| Zoom type                          | Fixed                                             | Product colour *                   | Black                                                                                                                                                                                                                              |
| Throw ratio                        | 0.22                                              | Display                            |                                                                                                                                                                                                                                    |
| Offset                             | 140%                                              | Built-in display *                 | ✗                                                                                                                                                                                                                                  |
| Video                              |                                                   | Power                              |                                                                                                                                                                                                                                    |
| Full HD *                          | ✓                                                 | Power source *                     | AC                                                                                                                                                                                                                                 |
| 3D *                               | ✓                                                 | Power consumption (typical) *      | 250 W                                                                                                                                                                                                                              |
| Supported graphics resolutions     | 640 x 480 (VGA), 3840 x 2160                      | Power consumption (standby) *      | 0.5 W                                                                                                                                                                                                                              |
| Supported video modes              | 480i, 480p, 576i, 576p, 720p, 1080i, 1080p, 2160p | AC input voltage                   | 100 - 240 V                                                                                                                                                                                                                        |
| Ports & interfaces                 |                                                   | AC input frequency                 | 50 - 60 Hz                                                                                                                                                                                                                         |
| HDMI connector type                | Full-size                                         | Operational conditions             |                                                                                                                                                                                                                                    |
| HDMI version                       | 2.0                                               | Operating temperature (T-T)        | 0 - 40 °C                                                                                                                                                                                                                          |
| USB 2.0 ports quantity             | 2                                                 | Weight & dimensions                |                                                                                                                                                                                                                                    |
| Headphone outputs                  | 1                                                 | Width                              | 451 mm                                                                                                                                                                                                                             |
| Serial interface type *            | RJ-45                                             | Depth                              | 332 mm                                                                                                                                                                                                                             |
| HDMI ports quantity *              | 2                                                 | Height                             | 100 mm                                                                                                                                                                                                                             |
| Component video (YPbPr/YCbCr) in * | 1                                                 |                                    |                                                                                                                                                                                                                                    |
| DVI port *                         | ✗                                                 |                                    |                                                                                                                                                                                                                                    |
| AC (power) in                      | ✓                                                 |                                    |                                                                                                                                                                                                                                    |
| Audio Return Channel (ARC)         | ✓                                                 |                                    |                                                                                                                                                                                                                                    |

| Network                     |       | Weight & dimensions              |                                                                                    |
|-----------------------------|-------|----------------------------------|------------------------------------------------------------------------------------|
| Smart TV *                  | ✗     | Weight *                         | 6.8 kg                                                                             |
| Ethernet LAN *              | ✓     | Package width                    | 577 mm                                                                             |
| Ethernet LAN (RJ-45) ports  | 1     | Package depth                    | 488 mm                                                                             |
| Wi-Fi *                     | ✓     | Package height                   | 187 mm                                                                             |
| Bluetooth                   | ✓     | Package weight                   | 10 kg                                                                              |
| Storage                     |       | Packaging content                |                                                                                    |
| Card reader integrated *    | ✗     | Remote control included *        | ✓                                                                                  |
| Internal storage capacity   | 32 GB | Remote control type              | IR                                                                                 |
| Features                    |       | Cables included                  | AC                                                                                 |
| Interactive *               | ✗     | Packaging content                | Power Cord: 1 Remote Control: 1 (w/ backlit) QSG: Yes Warranty Card: Yes (CN Only) |
| Noise level (economic mode) | 30 dB | Logistics data                   |                                                                                    |
| HDCP                        | ✓     | Quantity per pack                | 1 pc(s)                                                                            |
|                             |       | Pallet gross length              | 110 cm                                                                             |
|                             |       | Pallet gross width               | 110 cm                                                                             |
|                             |       | Pallet gross height              | 181 cm                                                                             |
|                             |       | Products per master (outer) case | 1 pc(s)                                                                            |
|                             |       | Harmonized System (HS) code      | 8528620000                                                                         |

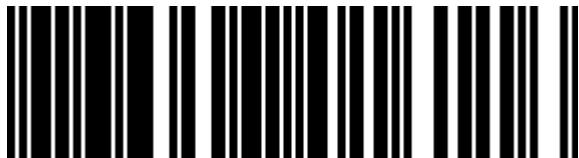

0766907016116



766907016116

### Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.