



APC Easy Rack PDU, Basic, 0U, 1 Phase, 3.7kW, 230V, 16A, 20 x C13 and 4 x C19 outlets, IEC60309 2P+E inlet

Brand : APC

Product code: EPDU1116B


Product name : Easy Rack PDU, Basic, 0U, 1 Phase, 3.7kW, 230V, 16A, 20 x C13 and 4 x C19 outlets, IEC60309 2P+E inlet

Easy Rack PDU, Basic, 0U, 1 Phase, 3.7kW, 230V, 16A, 20 x C13 and 4 x C19 outlets, IEC60309 2P+E inlet

APC Easy Rack PDU, Basic, 0U, 1 Phase, 3.7kW, 230V, 16A, 20 x C13 and 4 x C19 outlets, IEC60309 2P+E inlet. PDU types: Basic, Rack capacity: 0U, Type: Single-phase. AC outlets quantity: 24 AC outlet(s), AC outlet types: C13 coupler, C19 coupler, Power plug: IEC 60309. Cable length: 3 m. Nominal input voltage: 200/208/230 V, Maximum current: 16 A, AC input frequency: 50 - 60 Hz. Width: 62 mm, Depth: 44 mm, Height: 902 mm



Design		Operational conditions	
PDU types *	Basic	Operating temperature (T-T)	0 - 45 °C
Type	Single-phase	Storage temperature (T-T)	-25 - 65 °C
Rack capacity *	0U	Operating relative humidity (H-H)	5 - 95%
Mounting	Vertical	Storage relative humidity (H-H)	5 - 95%
Housing material	Aluminium	Operating altitude	0 - 3000 m
Product colour	Black	Non-operating altitude	0 - 9000 m
On/off switch	✗	Weight & dimensions	
Ports & interfaces		Width	62 mm
AC outlets quantity *	24 AC outlet(s)	Depth	44 mm
Power plug	IEC 60309	Height	902 mm
AC outlet types *	C13 coupler, C19 coupler	Weight	2.2 kg
Features		Packaging content	
Cable length	3 m	Manual	✓
Power		Packaging data	
Nominal input voltage *	200/208/230 V	Package weight	2.98 kg
AC input frequency	50 - 60 Hz	Package width	160 mm
Maximum current *	16 A	Package depth	110 mm
Nominal output voltage	230 V	Package height	1320 mm
Load capacity	3680 VA	Logistics data	
Maximum input current per phase	16 A	Total carbon footprint (kg of CO2e)	55.85
Maximum power	3680 W		

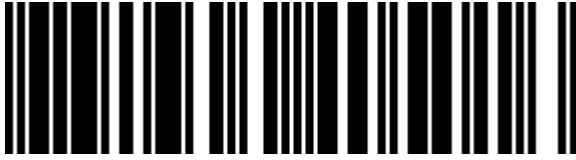

0731304405016



731304405016

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.