

StarTech.com 2x2 HDMI Matrix Switch - 4K with Fast Switching and Auto-sensing

Brand : StarTech.com

Product code: VS222HD4K

Product name : 2x2 HDMI Matrix Switch - 4K with Fast Switching and Auto-sensing



StarTech.com 2x2 HDMI Matrix Switch - 4K UltraHD HDMI Swtich with Fast Switching, Auto-sensing and Serial Control

StarTech.com 2x2 HDMI Matrix Switch - 4K with Fast Switching and Auto-sensing. Video port type: HDMI. Product colour: Black, Supported video modes: 1080p, LED indicators: Activity, Power. AC adapter input voltage: 100 - 240 V, AC adapter input current: 1.5 A, AC adapter output voltage: 12 V. Certification: CE, FCC. Package width: 235 mm, Package depth: 156 mm, Package height: 65 mm




Ports & interfaces		Packaging data	
Video port type *	HDMI	Package width	235 mm
HDMI version	1.4	Package depth	156 mm
HDMI in	2	Package height	65 mm
Number of HDMI outputs	2	Package weight	841 g
DC-in jack	✓	Packaging content	
Features		Quick start guide	✓
Product colour	Black	Remote control included	✓
HDCP	✓	Cables included	Phone (RJ-11)
Supported video modes	1080p	AC adapter included	✓
LED indicators	Activity, Power	Mounting brackets included	✓
Maximum resolution	3840 x 2160 pixels	Operational conditions	
Remote control type	IR	Operating temperature (T-T)	0 - 50 °C
Audio output channels	7.1 channels	Storage temperature (T-T)	-20 - 70 °C
Power		Operating relative humidity (H-H)	0 - 80%
AC adapter input voltage	100 - 240 V	Technical details	
AC adapter input current	1.5 A	Audio support	✓
AC adapter output voltage	12 V	Compliance certificates	RoHS
Certificates		Logistics data	
Certification	CE, FCC	Harmonized System (HS) code	85176990



0065030862271



065030862271

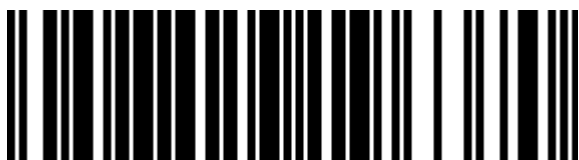

4058829196370

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.