


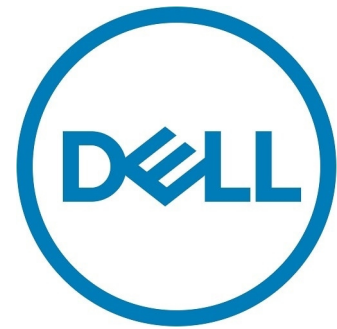

DELL 2X15K network transceiver module Fiber optic 100000 Mbit/s QSFP28 850 nm



Brand : DELL

Product code: 407-BBWW

Product name : 2X15K

100GbE QSFP28, SR4, MPO12, MMF

DELL 2X15K network transceiver module Fiber optic 100000 Mbit/s QSFP28 850 nm:

The Dell™ QSFP28 transceiver delivers fiber connectivity to extend the range of your network. This hot-pluggable transceiver with QSFP28 (Quad Form Factor Pluggable) footprint features a MPO-12 connector. The Dell networking 100GbE-SR4 QSFP28 transceiver provides 100GbE connectivity up to 100m .

Additionally, it provides a unique enhanced digital diagnostic monitoring interface, which allows real-time access to device operating parameters such as transceiver temperature, laser bias current, transmitted optical power, received optical power, and transceiver supply voltage.

DELL 2X15K. SFP transceiver type: Fiber optic, Maximum data transfer rate: 100000 Mbit/s, Interface type: QSFP28. Brand compatibility: Dell, Compatible products: - Networking S5232F-ON - Networking S5296F-ON - Networking S5248F-ON - Networking S5212F-ON - Quantity per pack: 1 pc(s)

Performance		Performance	
SFP transceiver type *	Fiber optic	Ethernet interface type	100 Gigabit Ethernet
Maximum data transfer rate *	100000 Mbit/s	Features	
Interface type *	QSFP28	Brand compatibility	Dell
Multi-mode fiber (MMF) supported	✓	Compatible products - Networking S5232F-ON - Networking S5296F-ON - Networking S5248F-ON - Networking S5212F-ON - Networking S5224F-ON	
Fiber optic connector	MPO12		
SFP transceiver standard	SR4		
Maximum transfer distance	100 m	Packaging content	
Wavelength	850 nm	Quantity per pack	1 pc(s)
		Logistics data	
		Harmonized System (HS) code	85369010



5397184377079



0884116375814



884116375814

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.