



HP Wired Desktop 320MK Mouse and Keyboard

Brand : HP

Product code: 9SR36AA

Product name : Wired Desktop 320MK Mouse and Keyboard

Wired Desktop 320MK Mouse and Keyboard

HP Wired Desktop 320MK Mouse and Keyboard:

Pro-class productivity for your workspace

Work efficiently and enhance your everyday productivity with the reliable HP Wired Desktop 320MK Mouse and Keyboard.

HP Wired Desktop 320MK Mouse and Keyboard. Keyboard form factor: Full-size. Keyboard style: Straight. Connectivity technology: Wired, Device interface: USB. Cable length: 1.8 m. Recommended usage: Office. Product colour: Black. Mouse included



Keyboard		Sustainability	
Recommended usage *	Office	Sustainability compliance	✓
Connectivity technology *	Wired	Sustainable technologies and materials	50% post-consumer recycled plastic
Device interface *	USB	Brand-specific features	
Pointing device *	✗	HP GTIN (EAN/UPC) with options	(ABB) 194721887689; (ABU) 194721887795
Keyboard form factor *	Full-size	HP GTIN (EAN/UPC)	194721887689, 194721887795
Numeric keypad *	✓	Weight & dimensions	
Country of origin	China	Keyboard dimensions (WxDxH)	426.2 x 110.9 x 16.7 mm
Design		Keyboard weight	413 g
Keyboard style	Straight	Mouse dimensions (WxDxH)	103.8 x 63.4 x 35.5 mm
Wrist rest	✗	Mouse weight	75.8 g
Product colour *	Black	Weight	413 g
Surface coloration	Monochromatic	Packaging content	
HP segment	Business	Number of products included *	1 pc(s)
Features		Warranty card	✓
Cable length	1.8 m	Technical details	
Power		General Product Safety Regulation (GPSR) URL	https://support.hp.com/us-en/document/ish_6126692-6126777-16?openCLC=true
Power source type *	USB	Other features	
Mouse		Compatibility	Compatible with PCs with available USB port.
Mouse included *	✓	Compatible operating systems	Windows 11; Windows 10
Mouse cable length	1.8 m	UNSPSC-code	43211733
System requirements		Logistics data	
Windows operating systems supported	Windows 10, Windows 11	Harmonized System (HS) code	84716060
Minimum system requirements	Windows 11; Windows 10 (64 and 32 bit); (UWP) RS4 and above		



0194721887993



194721887993



0194721887924



194721887924



0194721888020



194721888020



0194721987440



194721987440



0194721888013



194721888013



0194721888037



194721888037



0194721987457



194721987457



0194721888044



194721888044



0194721887931



194721887931



0194721887948



194721887948



0194721887955



194721887955



0194721887962



194721887962



0194721887979



194721887979



0194721887986



194721887986



0194721887580



194721887580



0194721887597



194721887597



0194721887603



194721887603



0194721887610



194721887610



0194721887627



194721887627



0194721887634



194721887634



0194721887641



194721887641



0194721887658



194721887658



0194721887665



194721887665



0194721887672



194721887672



0194721887573



194721887573



0194721887696



194721887696



0194721887702



194721887702



0194721887719



194721887719



0194721887726



194721887726



0194721887740



194721887740



0194721887757



194721887757



0194721887764



194721887764



0194721887771



194721887771



0194721887788



194721887788



0194721887795



194721887795



0194721887801



194721887801



0194721887818



194721887818



0194721887825



194721887825



0194721887832



194721887832



0194721887849



194721887849



0194721887863



194721887863



0194721887870



194721887870



0194721887887



194721887887



0194721887894



194721887894



0194721887900



194721887900



0194721887917



194721887917



0194721888006




194721888006



0195122692025



195122692025

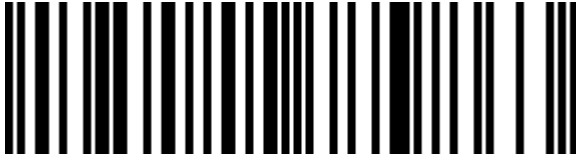

0195122779863




195122779863




5715063732854




5715063732922

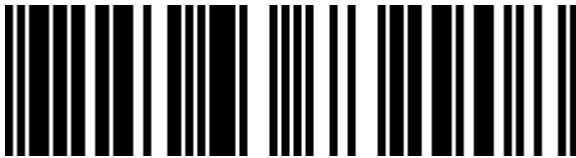

5715063732908

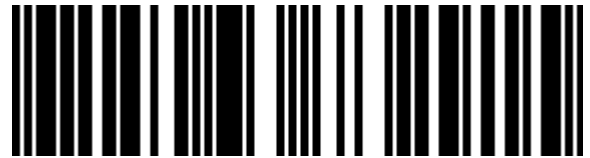

5715063732915

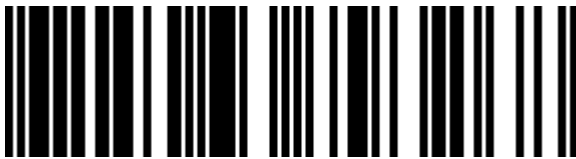

5715063793268

Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.