



Lenovo IBM TS4300 Storage array Tape Cartridge

Brand : Lenovo

Product code: 6741A3F




Product name : IBM TS4300

IBM TS4300 3U Tape Library-Expansion Unit

Lenovo IBM TS4300 Storage array Tape Cartridge:

TS4300 Tape Library
Standalone tape automation solution
The TS4300 is a high-density, highly scalable, easy-to-manage solution designed to keep data securely stored long-term, while reducing costs.
Lenovo IBM TS4300. Product type: Storage array, Media type: Tape Cartridge, Form factor: 3U. Width: 446 mm, Depth: 873 mm, Height: 133 mm. Host interface: 6Gb SAS, 8Gb FC

Performance		Operational conditions	
Product type *	Storage array	Operating temperature (T-T)	15 - 32 °C
Media type *	Tape Cartridge	Storage temperature (T-T)	5 - 45 °C
Form factor	3U	Operating relative humidity (H-H)	20 - 80%
Storage media types supported	LTO-6	Storage relative humidity (H-H)	8 - 80%
Product colour	Black	Other features	
Weight & dimensions		Host interface	6Gb SAS, 8Gb FC
Width	446 mm	Logistics data	
Depth	873 mm	Harmonized System (HS) code	84719000
Height	133 mm		
Weight	13 kg		

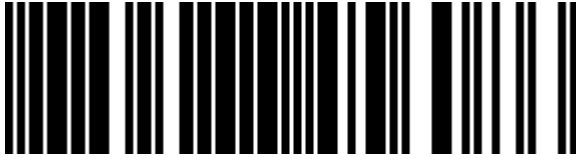

0889488456086



889488456086

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.