

Targus VersaVu 32.8 cm (12.9") Folio Black

Brand : Targus
Product code: THZ749GL
Product name : VersaVu

- Passes military grade 4’ drop testing* for robust protection
 - Patented 360° rotation for quick-switch portrait/landscape viewing
 - Patented custom-moulded tray with reinforced corners enhances impact protection
 - Adjusts in an instant to deliver virtually infinite viewing angles and comfortable typing position
 - Precision control, port and camera cut-outs deliver hassle-free listening and photos
 - Boosts sound with audio-scoops that direct sound toward user
 - Magnetic wrap closure ensures secure transport
 - Integrated Apple Pencil® holder which allows the pencil to charge with the case on – the magnetic flap also keeps the pencil secure
- Classic Case f / 12.9" iPad Pro® (2018), Black
Targus VersaVu. Case type: Folio, Brand compatibility: Apple, Compatibility: iPad Pro (2018), Maximum screen size: 32.8 cm (12.9"). Weight: 580 g



Features		Packaging data	
Compatibility *	iPad Pro (2018)	Package weight	600 g
Maximum screen size *	32.8 cm (12.9")	Logistics data	
Case type *	Folio	Harmonized System (HS) code	84733080
Material *	Polyurethane	Shipping (inner) case width	14.6 cm
Product main colour *	Black	Shipping (inner) case length	25.2 cm
Brand compatibility *	Apple	Shipping (inner) case height	35.1 cm
Closure type	Magnetic closure	Products per shipping (inner) case	5 pc(s)
Stand mode *	✓	Master (outer) case width	310 mm
Protection features	Scratch resistant, Shock resistant	Master (outer) case length	525 mm
Country of origin	China	Master (outer) case height	375 mm
Weight & dimensions		Master (outer) case gross weight	13.4 kg
Width	310 mm	Products per master (outer) case	20 pc(s)
Depth	230 mm	Shipping (inner) case net weight	3.22 kg
Height	28 mm	Products per pallet	400 pc(s)
Weight	580 g	Other features	
Packaging data		Bluetooth	✗
Quantity per pack	1 pc(s)		
Package width	25 mm		
Package depth	238.9 mm		
Package height	334 mm		



5051794025637




7330381778049



0092636331559



092636331559

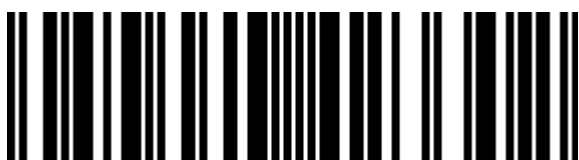

5054444423302

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.