



TP-Link Powerline 600 Wi-Fi 3-pack Kit

Brand : TP-Link

Product code: TL-WPA4220T KIT V4

Product name : Powerline 600 Wi-Fi 3-pack Kit

- Extend wired and wireless network to any room using existing electrical system
 - One-Touch Wi-Fi Extension - Wi-Fi Clone Button simplifies your Wi-Fi configuration and helps build a seamless unified home network
 - HomePlug AV standard providing up to 600 Mbps¹ high speed data transmission over a home's existing electrical wiring, ideal for lag-free HD or 3D video streaming and online gaming
 - Extend 300 Mbps wireless connections to previously hard-to-reach areas of your home and office
 - Two fast Ethernet ports of every extender enable TL-WPA4220 to run multiple high-speed and reliable wired connections for devices
- HomePlug AV, IEEE802.3, IEEE802.3u, IEEE802.11b/g/n, 2.4-2.4835GHz, 2 x 10/100Mbps



Performance		Power	
Type *	Network repeater	AC input voltage	220 V
Maximum transfer distance *	300 m	AC input frequency	50 Hz
Data transfer rate	300 Mbit/s	Power consumption (typical)	7.216 W
Ethernet LAN data rates	10,100 Mbit/s	Power consumption (max)	7.608 W
Windows operating systems supported	Windows 10, Windows 10 Education, Windows 10 Education x64, Windows 10 Enterprise, Windows 10 Enterprise x64, Windows 10 Home, Windows 10 Home x64, Windows 10 IOT Core, Windows 10 Pro, Windows 10 Pro x64, Windows 10 x64, Windows 2000, Windows 2000 Professional, Windows 7, Windows 7 Enterprise, Windows 7 Enterprise x64, Windows 7 Home Basic, Windows 7 Home Basic x64, Windows 7 Home Premium, Windows 7 Home Premium x64, Windows 7 Professional, Windows 7 Professional x64, Windows 7 Starter, Windows 7 Starter x64, Windows 7 Ultimate, Windows 7 Ultimate x64, Windows 8, Windows 8 Enterprise, Windows 8 Enterprise x64, Windows 8 Pro, Windows 8 Pro x64, Windows 8 x64, Windows 8.1, Windows 8.1 Enterprise, Windows 8.1 Enterprise x64, Windows 8.1 Pro, Windows 8.1 Pro x64, Windows 8.1 x64, Windows Vista, Windows Vista Business, Windows Vista Enterprise, Windows Vista Enterprise x64, Windows Vista Home Basic, Windows Vista Home Basic x64, Windows Vista Home Premium, Windows Vista Home Premium x64, Windows Vista Ultimate, Windows Vista Ultimate x64, Windows Vista x64, Windows XP, Windows XP Home, Windows XP Home x64, Windows XP Professional, Windows XP Professional x64	Operational conditions	
		Operating temperature (T-T)	0 - 40 °C
		Storage temperature (T-T)	-40 - 70 °C
		Operating relative humidity (H-H)	10 - 90%
		Storage relative humidity (H-H)	5 - 90%
		Weight & dimensions	
		Width	94 mm
		Depth	54 mm
		Height	69.5 mm
		Transmitter width	5.2 cm
		Transmitter depth	2.85 cm
		Transmitter height	6.5 cm
		Packaging content	
		Quick start guide	✓
		Packaging data	
		Package type	Box
		Package width	230 mm
		Package depth	190 mm
		Package height	100 mm
		Package weight	650 g
		Certificates	
		Compliance certificates	RoHS


Performance	
Mac compatibility	✓
Mac operating systems supported	✓
Linux operating systems supported	✓
Network	
Cabling technology	10/100Base-T(X)
Networking standards	IEEE 802.11b, IEEE 802.11g, IEEE 802.11n, IEEE 802.3, IEEE 802.3u
Wi-Fi	✓
Wi-Fi standards	802.11a, 802.11b, 802.11g, Wi-Fi 4 (802.11n)
Wi-Fi data rate (max)	500 Mbit/s
Wi-Fi band	Single-band (2.4 GHz)
Bandwidth	2.4 GHz
Security algorithms	64-bit WEP, 128-bit WEP, WPA-PSK, WPA2, WPA2-PSK
Ports & interfaces	
Ethernet LAN (RJ-45) ports	2
Design	
Product colour *	White
Mounting type	Wall
LED indicators	Network, PLC, Power, WLAN
Certification	CE, RoHS



6935364032531




6935364032548

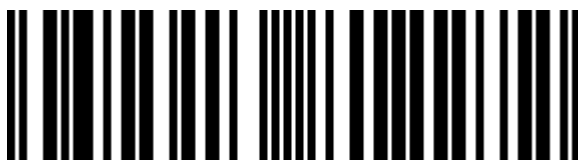

5052916812272




5054533107663

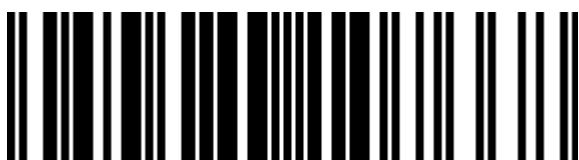

5054484107668



5054230594933

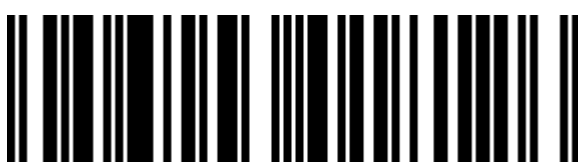

4056203018126




5054629940334



6935364086879



8592978178826

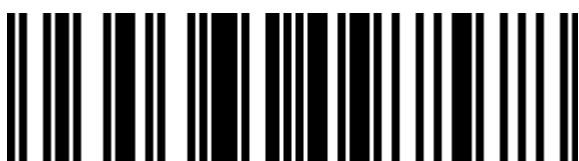

6935364097578



1210002614801

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.