

StarTech.com 90x25mm High Air Flow Dual Ball Bearing Computer Case Fan w/ TX3

Brand : StarTech.com

Product code: FAN9X25TX3H

Product name : 90x25mm High Air Flow Dual Ball Bearing Computer Case Fan w/ TX3

StarTech.com 90x25mm High Air Flow Dual Ball Bearing Computer Case Fan w/ TX3

StarTech.com 90x25mm High Air Flow Dual Ball Bearing Computer Case Fan w/ TX3:

Add additional chassis cooling with a 90mm high flow case fan

This 9.25cm x 9.25cm x 25mm (2600 RPM) computer case fan helps prevent computer systems from overheating, thereby increasing efficiency and stability.

Featuring a TX3 motherboard connection, the FAN9X25TX3H is a high-performance way to avoid overheating and system failure.

The StarTech.com Advantage

- A dual ball bearing design ensures reliability and longer life
- A built-in tachometer allows for easy monitoring of the fan performance
- Higher performance fan with Increased air flow for warmer environments or higher performance components

StarTech.com 90x25mm High Air Flow Dual Ball Bearing Computer Case Fan w/ TX3. Type: Fan. Product colour: Black

Performance		Weight & dimensions	
Suitable location *	Computer case	Package height	186 mm
Type *	Fan	Package weight	130 g
Noise level (high speed)	33 dB	Technical details	
Operating temperature (T-T)	-10 - 80 °C	Bearing technology	Ball bearing
Design		Other features	
Product colour *	Black	Dimensions (WxDxH)	92 x 92 x 25 mm
Weight & dimensions		Airflow	50.2
Weight	108 g	Rotational speed	2600 RPM
Package width	26 mm	Logistics data	
Package depth	157 mm	Harmonized System (HS) code	84733080





0065030788946




065030788946



0033585420864



033585420864

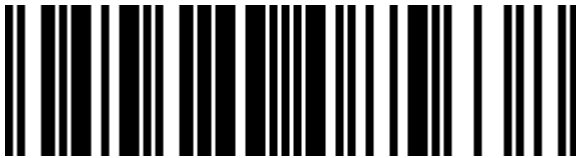

5054484085638

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.