


Allied Telesis AT-SPSX-90 network transceiver module Fiber optic 1000 Mbit/s SFP 850 nm

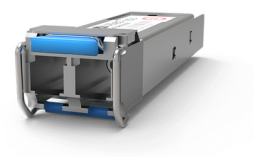

Brand : Allied Telesis

Product code: AT-SPSX-90

Product name : AT-SPSX-90

- Fiber and copper solutions
- Compact size
- Flexible architecture
- Plug and Play for ease of use
- Self-locking mechanism
- MSA-compliant

1000SX SFP, LC, MMF, 850 nm, TAA

Allied Telesis AT-SPSX-90. SFP transceiver type: Fiber optic, Maximum data transfer rate: 1000 Mbit/s, Interface type: SFP. Product colour: Silver, Housing material: Metal. Quantity per pack: 1 pc(s). RX sensitivity: -19 dB

Performance		Features	
SFP transceiver type *	Fiber optic	Product colour	Silver
Maximum data transfer rate *	1000 Mbit/s	Housing material	Metal
Interface type *	SFP	Plug and Play	✓
Multi-mode fiber (MMF) supported	✓	Hot-swap	✓
Fiber optic connector	LC	Operational conditions	
Maximum transfer distance	550 m	Operating temperature (T-T)	-40 - 105 °C
Wavelength	850 nm	Packaging content	
Tx power (min)	-8 dBmW	Quantity per pack	1 pc(s)
Tx power (max)	-3 dBmW	Other features	
Link budget	11 dB	RX sensitivity	-19 dB



0767035173276



767035173276

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.