

Viewsonic VB-STND-008 multimedia cart/stand Black Universal Multimedia cart/trolley

Brand : Viewsonic

Product code: VB-STND-008

Product name : VB-STND-008


- Integrated ViewBoard on-screen control for better lesson delivery
- Electric tilt adjustment for effortless individual or group learning
- Motorized height adjustment for easy and fast access to ViewBoard
- Accessible design with large wheels for maximum mobility
- Smart space design to keep all cables and accessories organized

1x VESA <800 x 600, <75 kg, 1248.9 x (1330.7 ~ 1890.7) x 706 mm

Viewsonic VB-STND-008. Product colour: Black, Recommended usage: Universal, Type: Multimedia cart/trolley. Height: 1890.7 mm, Height adjustment: 56 cm, Width: 1248.9 mm. Package width: 1150 mm, Package depth: 1010 mm, Package height: 490 mm. Products per master (outer) case: 1 pc(s), Pallet gross length: 101.6 cm, Pallet gross width: 121 cm



Features		Features	
Product colour *	Black	Certification	cTUVus, FCC, Mexican(NOM), UL1678, CE, CB, RoHS, ErP, REACH, WEEE, RCM
Material	Aluminium, Plastic, Steel	Weight & dimensions	
Recommended usage *	Universal	Height	1890.7 mm
Type *	Multimedia cart/trolley	Height adjustment	56 cm
Maximum weight capacity	75 kg	Width	1248.9 mm
Maximum weight per shelf (capacity)	10 kg	Depth	716 mm
Number of displays supported	1	Weight	65 kg
Minimum screen size	139.7 cm (55")	Packaging data	
Maximum screen size	2.18 m (86")	Package width	1150 mm
VESA mounting	✓	Package depth	1010 mm
Panel mounting interface	800 x 600 mm	Package height	490 mm
Tilt angle range	0 - 90°	Package weight	74.4 kg
Swivel angle	360°	Packaging content	
Number of shelves	1 shelves	Quick start guide	✓
External AC outlets quantity	1 AC outlet(s)	Logistics data	
Number of wheels	4 wheel(s)	Products per master (outer) case	1 pc(s)
Height adjustment	✓	Pallet gross length	101.6 cm
Height adjustment type	Electric	Pallet gross width	121 cm
Cable management	✓	Pallet gross height	2.08 m
		Harmonized System (HS) code	9403208000

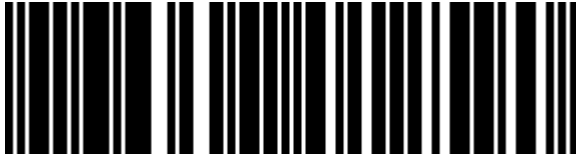

0766907012590



766907012590

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.