



APC Easy UPS On-Line, 3kVA, Lithium-ion, Rack/Tower 4U, 230V, 6 IEC C13 + 1 IEC C19 outlets, Intelligent Card Slot, Extended runtime, W/ rail kit

Brand : APC

Product code: SRVL3KRILRK

Product name : Easy UPS On-Line, 3kVA, Lithium-ion, Rack/Tower 4U, 230V, 6 IEC C13 + 1 IEC C19 outlets, Intelligent Card Slot, Extended runtime, W/ rail kit




Easy UPS On-Line, 3kVA, Lithium-ion, Rack/Tower 4U, 230V, 6 IEC C13 + 1 IEC C19 outlets, Intelligent Card Slot, Extended runtime, W/ rail kit
APC Easy UPS On-Line, 3kVA, Lithium-ion, Rack/Tower 4U, 230V, 6 IEC C13 + 1 IEC C19 outlets, Intelligent Card Slot, Extended runtime, W/ rail kit. UPS topology: Double-conversion (Online), Output power capacity: 3 kVA, Output power: 2700 W. AC outlet types: C13 coupler, C19 coupler, Power plug: C20 coupler, AC outlets quantity: 7 AC outlet(s). Battery technology: Lithium-Ion (Li-Ion), Battery voltage: 48 V, Typical backup time at full load: 45 min. Form factor: Rackmount/Tower, Product colour: Black, Rack capacity: 4U. Compliance certificates: CE, RoHS, UKCA, Certification: CB , CE, EAC, IEC 62619, KC, RCM, TISI, UKCA, UN 38.3, RoHS



Features		Battery	
UPS topology *	Double-conversion (Online)	Typical backup time at half load	88 min
Output power capacity *	3 kVA	Battery life (max)	10 year(s)
Output power *	2700 W	Battery recharge time	4.8 h
Waveform *	Sine	Design	
Input operation voltage (min) *	110 V	Form factor *	Rackmount/Tower
Input operation voltage (max) *	300 V	Rack capacity	4U
Input frequency *	40/70 Hz	Cooling type	Active
Output operation voltage (max)	230 V	Built-in fan	✓
Output frequency	50/60 Hz	Product colour *	Black
Surge energy rating	945 J	Control type	Buttons
Efficiency	90%	Display type	LCD
Crest factor	3:1	International Protection (IP) code	IP20
ECO mode	✓	Operational conditions	
Emergency Power Off (EPO)	✓	Storage temperature (T-T)	-20 - 50 °C
Noise level	50 dB	Operating relative humidity (H-H)	0 - 95%
Audible alarm(s)	✓	Storage relative humidity (H-H)	0 - 95%
Audible alarm modes	Low battery alarm, Overload alarm	Non-operating altitude	0 - 15000 m
Power source type	AC	Certificates	
Detachable power cord	✓	Compliance certificates	CE, RoHS, UKCA
Ports & interfaces		Certification	CB , CE, EAC, IEC 62619, KC, RCM, TISI, UKCA, UN 38.3, RoHS
AC outlet types	C13 coupler, C19 coupler	Packaging content	
Power plug	C20 coupler	Rack mount kit	✓
AC outlets quantity	7 AC outlet(s)	Cables included	Phone (RJ-11), Power load cable, RJ-45, RS-232, USB cable
USB port	✓	Management card included	✗
RS-232 ports	1	Manual	✓
Modem (RJ-11) ports	1		
Ethernet LAN (RJ-45) ports	1		
SmartSlot	✓		

Ports & interfaces		Weight & dimensions	
SmartConnect port	×	Width	438 mm
Battery		Depth	616 mm
Battery technology	Lithium-Ion (Li-Ion)	Height	172 mm
Battery voltage	48 V	Weight	38.3 kg
Typical backup time at full load	45 min	Packaging data	
		Package width	800 mm
		Package depth	600 mm
		Package height	480 mm
		Package weight	50.6 kg

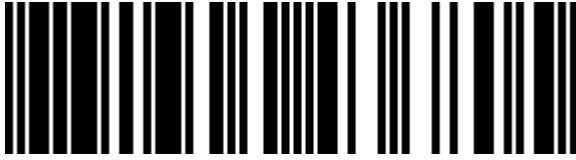

0731304436805



731304436805



8592978530730

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.