

Viewsonic CDE7530 Signage Display 190.5 cm (75") Wi-Fi 450 cd/m² 4K Ultra HD Black Built-in processor Android 11

Brand : Viewsonic


Product code: CDE7530

Product name : CDE7530

- Wireless presentation for upgraded efficiency
- Single cable via USB-C with 65W power delivery
- 24/7 Sustainable video playback for continuous communication
- Remote device management with myViewBoard Manager
- ProAV compatibility with Crestron, Extron, and AMX


75", TFT LCD, 1649.664 x 927.936, 3840 x 2160p, 1.07G, 450nits, 1200:1, 8ms, 4GB, 32GB, HDMI 2.1 x3, RS-232, WIFI slot, SPDIF x1, RJ45 x1, Type-A 2.0 x 1, 3.0 x1, 10w x 2, Android 11, 100 - 240V, 34.65kg, 1685.6 x 963.7 x 81.6mm

Viewsonic CDE7530. Display diagonal: 190.5 cm (75"), Display resolution: 3840 x 2160 pixels, Display brightness: 450 cd/m², HD type: 4K Ultra HD. Wi-Fi. Operating system installed: Android 11. Product colour: Black

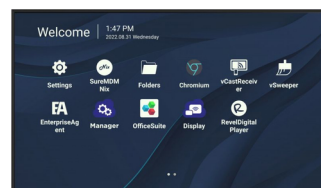

Display		Power	
Panel type	TFT	Energy efficiency scale	A to G
LED backlighting type	Direct-LED	Computer system	
Display diagonal *	190.5 cm (75")	Built-in processor *	✓
Display resolution *	3840 x 2160 pixels	Processor architecture	ARM Cortex-A55
Display brightness *	450 cd/m ²	Processor cores	4
HD type *	4K Ultra HD	Operating system installed	Android 11
Touchscreen *	✗	Weight & dimensions	
Native aspect ratio	16:9	Display width	1685.6 mm
Response time	8 ms	Display depth	81.6 mm
Contrast ratio (typical)	1200:1	Display height	963.7 mm
Contrast ratio (dynamic)	5000:1	Display weight	34.6 kg
Viewing angle, horizontal	178°	Weight	34.6 kg
Viewing angle, vertical	178°	Packaging data	
Display number of colours	1.07 billion colours	Package width	1863 mm
Ports & interfaces		Package depth	225 mm
HDMI ports quantity *	4	Package height	1090 mm
DisplayPort version	1.2	Package weight	48.1 kg
USB connector type	USB Type-A	Packaging content	
USB 3.2 Gen 1 (3.1 Gen 1) Type-A ports quantity	1	Remote control included	✓
USB Power Delivery up to	65 W	Cables included	HDMI, Power, RS-232, USB Type-C
USB Type-C DisplayPort Alternate Mode	✓	Mounting kit	✓
Ethernet LAN (RJ-45) ports	1	Operational conditions	
Audio		Operating temperature (T-T)	0 - 40 °C
Built-in speaker(s) *	✓	Operating relative humidity (H-H)	10 - 90%
Number of built-in speakers	2	Logistics data	
Design		Products per master (outer) case	5 pc(s)
Product colour *	Black	Pallet gross length	114 cm
VESA mounting *	✓	Pallet gross width	195 cm
Panel mounting interface	600 x 600 mm	Pallet gross height	121.9 cm
Anti-glare screen	✓	Harmonized System (HS) code	8528521000

Power		Network	
Power consumption (typical) *	170 W	Ethernet LAN *	✓
Power consumption (off)	0.5 W	Wi-Fi *	✓
Energy efficiency class (SDR)	G	Technical details	
Energy consumption (SDR) per 1000 hours	232 kWh	OPS slot	1
AC input voltage	100 - 240 V	Other features	
		Manual	✓
		USB 2.0 ports quantity	1

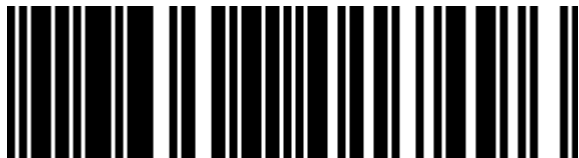

0766907017496



766907017496

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.