

Viewsonic CDE9830 Signage Display 2.49 m (98") Wi-Fi 500 cd/m² 4K Ultra HD Black Built-in processor Android 11

Brand : Viewsonic



Product code: CDE9830

Product name : CDE9830

- Wireless presentation for upgraded efficiency
- Single cable via USB-C with 65W power delivery
- 24/7 Sustainable video playback for continuous communication
- Remote device management with myViewBoard Manager
- ProAV compatibility with Crestron, Extron, and AMX


98", TFT LCD, 2158.848 x 1214.352, 3840 x 2160p, 1.07G, 500nits, 1200:1, 8ms, 4GB, 32GB, HDMI 2.1 x3, RS-232, WIFI slot, SPDIF x1, RJ45 x1, Type-A 2.0 x 1, 3.0 x1, 10w x 2, Android 11, 100 - 240V, 69.4kg, 87.12 x 49.94 x 3.11"

Viewsonic CDE9830. Display diagonal: 2.49 m (98"), Display resolution: 3840 x 2160 pixels, Display brightness: 500 cd/m², HD type: 4K Ultra HD. Wi-Fi. Operating system installed: Android 11. Product colour: Black

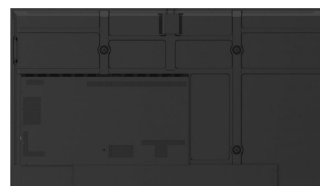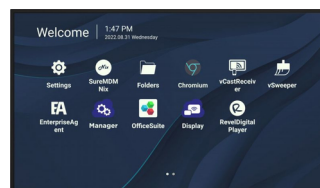

Display		Power	
Panel type	TFT	AC input voltage	100 - 240 V
LED backlighting type	Direct-LED	Energy efficiency scale	A to G
Display diagonal *	2.49 m (98")	Computer system	
Display resolution *	3840 x 2160 pixels	Built-in processor *	✓
Display brightness *	500 cd/m ²	Processor architecture	ARM Cortex-A55
HD type *	4K Ultra HD	Processor cores	4
Touchscreen *	✗	Operating system installed	Android 11
Native aspect ratio	16:9	Weight & dimensions	
Response time	8 ms	Display width	2212.9 mm
Contrast ratio (typical)	1200:1	Display depth	79 mm
Contrast ratio (dynamic)	5000:1	Display height	1268.4 mm
Viewing angle, horizontal	178°	Display weight	69.4 kg
Viewing angle, vertical	178°	Weight	69.4 kg
Display number of colours	1.07 billion colours	Packaging data	
Ports & interfaces		Package width	2360 mm
HDMI ports quantity *	4	Package depth	280 mm
HDMI version	2.1	Package height	1425 mm
HDMI output ports quantity	1	Package weight	90.3 kg
DisplayPort version	1.2	Packaging content	
USB connector type	USB Type-A	Remote control included	✓
USB 3.2 Gen 1 (3.1 Gen 1) Type-A ports quantity	1	Cables included	HDMI, Power, RS-232, USB Type-C
USB Power Delivery (USB PD)	✓	Mounting kit	✓
USB Power Delivery up to	65 W	Operational conditions	
USB Type-C DisplayPort Alternate Mode	✓	Operating temperature (T-T)	0 - 40 °C
Ethernet LAN (RJ-45) ports	1	Operating relative humidity (H-H)	10 - 90%
Audio		Logistics data	
Built-in speaker(s) *	✓	Products per master (outer) case	4 pc(s)
Number of built-in speakers	2	Pallet gross length	114 cm
Design		Pallet gross width	2.38 m
Product colour *	Black	Pallet gross height	155.4 cm
VESA mounting *	✓	Harmonized System (HS) code	8528521000
Panel mounting interface	800 x 600 mm	Network	
Anti-glare screen	✓	Ethernet LAN *	✓

Power		Network	
Power consumption (typical) *	229 W	Wi-Fi *	✓
Power consumption (off)	0.5 W	Features	
Energy efficiency class (SDR)	G	Wall mountable	✓
Energy consumption (SDR) per 1000 hours	309 kWh	Technical details	
		OPS slot	1
		Other features	
		Manual	✓
		USB 2.0 ports quantity	1

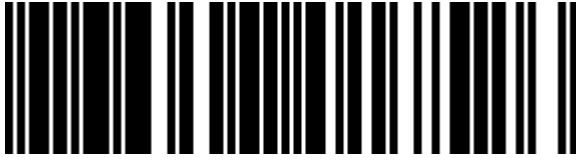

0766907017526



766907017526

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.