


ASUS ESC4000 G4 Intel® C621 LGA 3647 (Socket P) Rack (2U) Black, Silver

Brand : ASUS

Product code: 90SF0071-M00340

Product name : ESC4000 G4

- Powered by Intel Xeon Scalable Platform
 - 150W CPU with 16 DIMM support
 - Flexible choice on versatile accelerators
 - Maximum flexible 8+3 expansion slots in a 2U server
 - Expandable storage for faster transfer speeds — NVMe port-to-port design and one M.2 slot with 2280-size SSD support
 - High power-efficiency with 1+1 redundant 1600W 80 plus (platinum level) power supply
 - User-friendly design for easier server maintenance — tool-less chassis design for installation and removal
 - Fully integrated remote server management — ASUS Control Center IT management software and ASMB9-iKVM module support
 - Smart thermal design for energy efficiency — reduces fan power consumption by up to 20%
- Intel Xeon Scalable, Intel C621, PCI-E 3.0 x16, 3.5" HDD, Aspeed AST2500, 2U

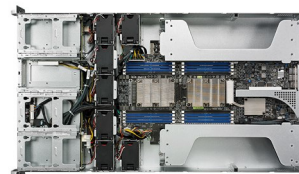

Processor		Network	
Built-in processor *	✓	Ethernet interface type	Fast Ethernet, Gigabit Ethernet
Motherboard chipset *	Intel® C621	Ethernet LAN data rates	10,100,1000 Mbit/s
Processor socket *	LGA 3647 (Socket P)	LAN controller	Intel® I350-AM2
Processor family	Intel® Xeon® Scalable	Ports & interfaces	
Number of processors supported *	2	USB 2.0 ports quantity *	2
Memory		USB 3.2 Gen 1 (3.1 Gen 1) Type-A ports quantity	4
Number of DIMM slots *	16	Ethernet LAN (RJ-45) ports *	3
Supported memory types *	DDR4-SDRAM	VGA (D-Sub) ports quantity	1
Supported DIMM module capacities	4GB, 8GB, 16GB, 32GB, 64GB	Expansion slots	
Maximum internal memory	2 TB	PCI Express slots version	3.0
Maximum RDIMM memory	64 GB	PCI Express x16 slots	8
Storage		Logistics data	
Number of storage drives supported *	8	Harmonized System (HS) code	84714100
Hot-swap HDD bays *	✓	Design	
Storage drive sizes supported	2.5, 3.5"	Chassis type *	Rack (2U)
Supported storage drive interfaces	M.2	Product colour	Black, Silver
Graphics		LED indicators	HDD, LAN, Power
On-board graphics card model	Aspeed AST2500	Operational conditions	
On-board graphics card memory	64 MB	Operating temperature (T-T)	10 - 35 °C
		Operating relative humidity (H-H)	20 - 90%
		Weight & dimensions	
		Width	440 mm
		Depth	800 mm
		Height	88 mm



4712900956603

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.