


# Technical datasheet: KPI-G2610A-K6268

## Specifications:

Operating Temperature	-20°C to +60°C
Storage Temperature	-30°C to +70°C
Rated Voltage	12VDC
Operating Voltage	3VDC to 24VDC
Max. Rated Current	8mA at 12VDC
Resonant Frequency	3.3kHz $\pm$ 0.5kHz
Min SPL	78dB / 12VDC / 30cm
Weight	2.5g
Case Material/Color	ABS/Black
Tone Nature	Continuous

## Dimensions:

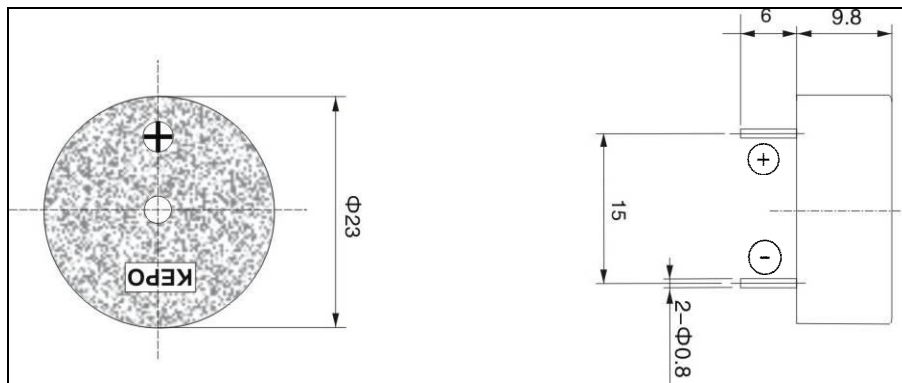

## Frequency Response:

