


# Technical datasheet: KP5083SP1-5844

## Specifications:

Input power	Rated 0.5W / Max. 1.0W
Impedance	$8\Omega \pm 15\%\Omega$ (1Vrms at 1kHz)
Frequency Range	0Hz to 10kHz
Resonant Frequency	$330\text{Hz} \pm 20\%\text{Hz}$
Distortion	<10% Max. at 2kHz/0.1W/0.1m
Out-diameter	$\varnothing 50\text{mm}$
Height	8.3mm
Weight	13.2g
SPL	$91\text{dB} \pm 3\text{dB}$ (0.1W/0.1M AVG at 1.0,1.2,1.5,2.0KHz)
Buzz and Rattle	No audible buzzes, rattles when 2.0V sine wave signal is swept at frequency range.

## Dimensions:

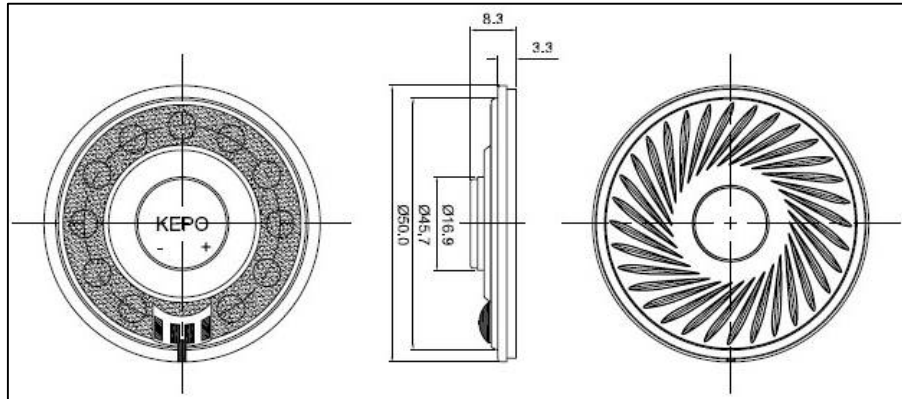

## Frequency Response:

