


Technical datasheet: KPM-G1612A-K6328

Specifications:

Operating Temperature	-30°C to +80°C
Storage Temperature	-40°C to +85°C
Rated Voltage	12VDC
Operating Voltage	6VDC to 18VDC
Max. Rated Current	40mA at 12VDC
Resonant Frequency	2048Hz
Min SPL	85dB/ 12VDC/ 2048Hz/ 10cm
Coil Resistance	115Ω±12Ω
Coil Impedance	200Ω
Weight	7g
Case Material/Color	MPP0/Black

Dimensions:

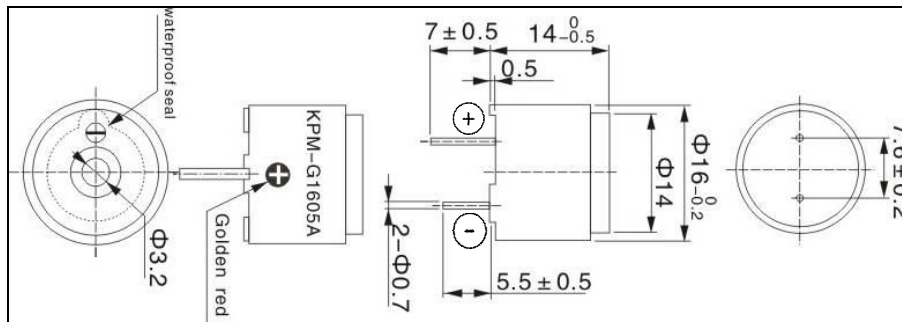

Frequency Response:

