


Technical datasheet: KPI-G2329-K6261

Specifications:

| | |
|-----------------------|---------------------|
| Operating Temperature | -20°C to +80°C |
| Storage Temperature | -30°C to +100°C |
| Rated Voltage | 12VDC |
| Operating Voltage | 8VDC to 24VDC |
| Max. Rated Current | 15mA at 12VDC |
| Resonant Frequency | 2.9kHz \pm 0.5kHz |
| Min SPL | 85dB / 12VDC / 30cm |
| Weight | 5g |
| Case Material/Color | PC/Black |
| Tone Nature | Continuous |

Dimensions:

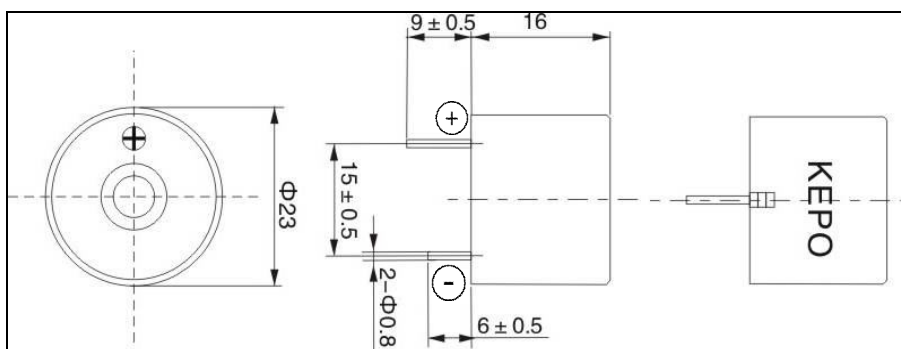

Frequency Response:

