


Technical datasheet: KPI-G4310-230VAC-K6296

Specifications:

Operating Temperature	-20°C to +80°C
Storage Temperature	-30°C to +100°C
Rated Voltage	230VAC
Operating Voltage	200VAC to 240VAC
Max. Rated Current	20mA at 230VAC
Resonant Frequency	2.9kHz \pm 0.5kHz
Min SPL	80dB / 230VAC / 60cm
Weight	40g
Case Material/Color	PBT/Black
Tone Nature	Continuous

Dimensions:

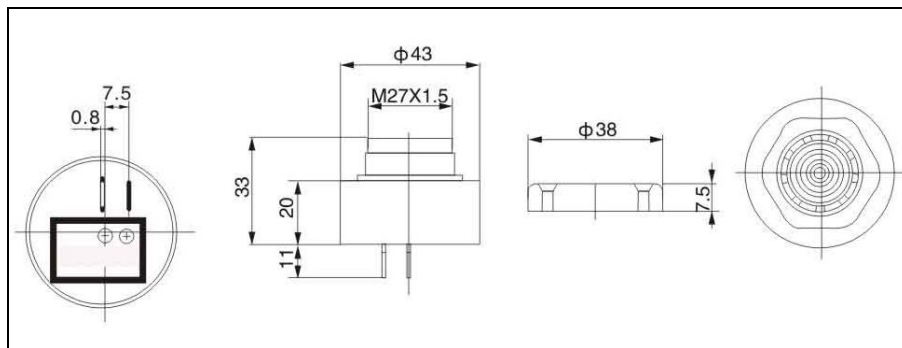

Frequency Response:

